


Rittal – The System.

Faster – better – everywhere.

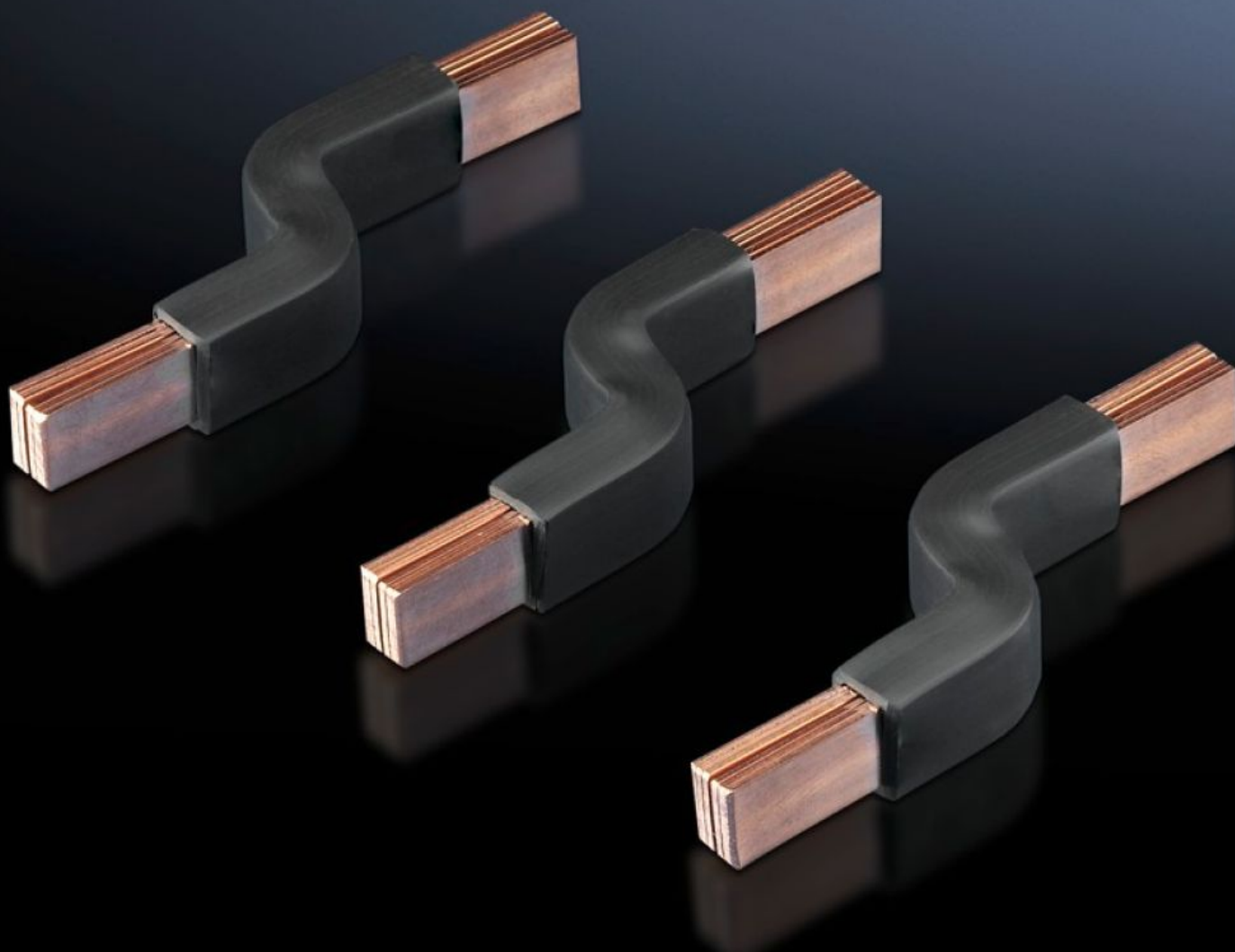

SV 9342.570

Priključni nosilec

State: 26.6.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9342.570 - Priključni nosilec za adapterje komponent odklopnika

Predsestavljena, laminirana ploščata bakrena žica za priklop komercialno dostopnih odklopnikov.



Features

Št. Modela	SV 9342.570
Opis izdelka	Predsestavljena, laminirana ploščata bakrena žica za priklop standardnih kompaktnih odklopnikov.
Material	Elektrolitski baker F20
Opomba	Univerzalna uporaba za stikalne naprave z razliko dimenzij med montažno ravnino in zgornjim robom kontaktne ravni 20 ± 5 mm.
Za model št.	9342.500 9342.510 9342.540 9342.550
Laminirana ploščata bakrena oblika	Število lamel: 6 Širina membrane: 9 mm Debelina membrane: 0,8 mm
Primerno za proizvajalca (tip)	ABB (T1, T1 UL, T2, T2 UL) Eaton (NZM1, NZM1 UL, BZM B1) Schneider Electric (NSC100, NSE75, NSE100)
Paketi	3 pc(s).
Neto teža	0,096 kg
Bruto teža	0,103 kg

Features

Teža bakra (kg na kos)	0,032
Carinska tarifna številka	85446010
ETIM 9	EC002270
ECLASS 8.0	27409221
Opis izdelka	SV Connection bracket E-Cu, for circuit-breaker component adaptor, SV 9342500/510/540/550

Approvals

Explanations	Declaration of conformity Declaration of conformity UK
--------------	---