

# Rittal – The System.

Faster – better – everywhere.



## RX 9360.730

## RiLineX component adaptor

State: 7.7.2026 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.730 - RiLineX component adaptor

RiLineX component adaptor (40 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

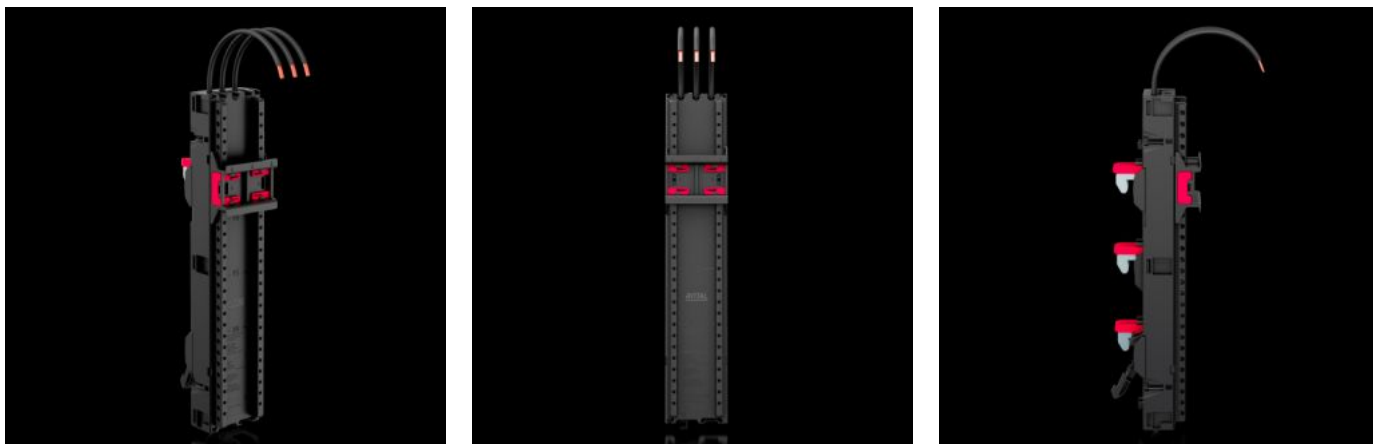

## Features

Št. Modela	RX 9360.730
Zasnova	S priključnim kablom
Prednosti	For mounting equipment for top hat rail installation, e.g. motor starter Pre-assembled connection cable Simple clip locking for support rails Optional anti-slip guard Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) Enostavna montaža Coordinated accessories reduce the number of different items required
Material	Poliamid (PA 6) Protipožarna zaščita v skladu z UL 94
Barva	RAL 9005 RAL 35745
Priključni kabli (AWG)	AWG 10
Nazivni tok (maks.)	40 A

# Features

Rated current of round conductor	40 A
Rated current of round conductor (UL)	40 A
Kabelska vtičnica	Bottom
Za sisteme palic z razmakom med središči	60 mm
Dolžina priključnega kabla	160 mm
Število polov	3-pole
Za namestitev sistema zbiralnih sponk	RiLineX RiLine60
Mere	Širina: 45 mm Višina: 239,4 mm Globina: 36,2 mm
Podporne tirnice količina/višina	1 / 10 mm
Za namestitev zbiralnih sponk	15 x 5/10 20 x 5/10 30 x 5/10
Rated voltage	690 V AC 600 V AC (UL) 600 V DC (UL)
Stopnja kontaminacije	3
Standardi	IEC 61 439-1/-2 UL 508
Nazivna impulzna vzdržna napetost Uimp	8 kV
Rated insulation voltage Ui	1.000 V
IP razred zaščite po IEC 60 529	IP 2XB
Maximum operating air humidity	90 %
Delovno temperaturno območje	-5 °C...55 °C
Temperaturno območje shranjevanja	-25 °C...75 °C

# Features

Vlažnost okolice (brez kondenzacije)	10...90 %
Fire load	3,419 MJ/m <sup>2</sup>
Paketi	4 pc(s).
Neto teža	1,42 kg
Bruto teža	1,45 kg
Teža bakra (kg na kos)	0,088
PCF na paket (od zibelke do vrat)	9,34
Carinska tarifna številka	85369095
ETIM 9	EC001531
Opis izdelka	RiLineX component adaptor (40 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

# Approvals

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity PCF-declaration