


Rittal – The System.

Faster – better – everywhere.

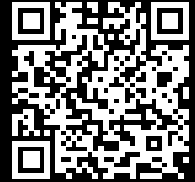

SV 9629.010

Mini-PLS component adaptor

State: 5.4.2026 (Source: rittal.com/si-sl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9629.010 - Mini-PLS component adaptor

Maximum rated current from 12 A to 100 A.

Features

Model No.	SV 9629.010
Material	Polyamide Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Connection cables (AWG)	AWG 12
Rated operating voltage	690 V, 3~
Rated current max.	25 A
Dimensions	Width: 90 mm Height: 160 mm
Support rails Qty/height	1 / 7.5 mm
Packs of	1 pc(s).
Net weight	0,42 kg
Gross weight	0,515 kg
Copper weight (kg per piece)	0,041
Customs tariff number	85369095
ETIM 9	EC001531
ECLASS 8.0	27370304
Product description	SV Mini-PLS component adaptor, 25 A, 690 V, 3-pole, connection cable AWG 12, WH: 90x160 mm, support rail H: 7,5 mm

Approvals

Approvals

Explanations

Declaration of conformity

Declaration of conformity UK