

# Rittal – The System.

Faster – better – everywhere.



## AX 2262.150

## Nástenné skrinky AX, trojdielne

State: 19.6.2026 (Source: [rittal.com/sk-sk](http://rittal.com/sk-sk))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2262.150 - Nástenné skrinky AX, trojdielne

The delivery concept of the three-part AX wall-mounted enclosures reduces complexity and enhances flexibility. The AX/VX modular system makes these enclosures suitable for a range of applications. The three-part structure ensures easy access.

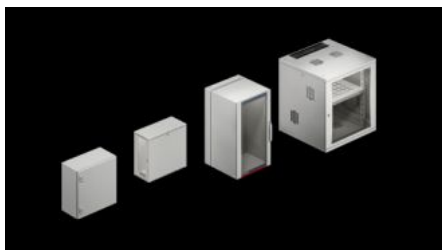

## Features

Obj. č.	AX 2262.150
Prevedenie	Nástenná skriňa IT
Materiál	Nástenný a otočný diel: ocelový plech, 1,5 mm Sklenené okno: jednovrstvové bezpečnostné sklo, 3 mm
Povrch	Štruktúrovaná prášková farba
Farba	Nástenný a otočný diel: RAL 7035 Presklené dvere: RAL 7035/7015 (bridlicovo šedá)
Rozsah dodávky	Stenový diel: prírubová doska uzavretá, horná a dolná Otočný diel s rastrom dierovania 25 mm v čelnom a zadnom ráme a dvoma 19" profilovými lištami, vpredu, pevná montáž Dizajnové presklené dvere Zámok stredného dielu: 3 mm Doppelbart Zámok dizajnových presklených dverí: bezpečnostný zámok 3524 E Komfortná rukoväť pre zámkové vložky a 2-bodové zamykanie
Výškové moduly	21 U
Rozmery	Šírka: 600 mm Výška: 1.012 mm Hĺbka: 573 mm
Inštalačná hĺbka	520 mm
Svetlé rozmery	Svetlá šírka: 502 mm Svetlá výška: 951 mm

# Features

Hĺbka otočného dielu	416 mm
Hĺbka nástenného dielu	135 mm
Počet uzáverov	1
Zaťažiteľnosť otočného dielu (statická)	750 N
Load capacity of wall section (static)	250 N
Základný materiál	Sheet steel
Uzáver	Vykonanie uzáveru: 2-bodové zamykanie Vložka uzáveru: Komfortná rukoväť a dvojbodová aretácia
Stupeň krytia IP podľa normy EN 60 529	IP 54 in conjunction with solid gland plate top and bottom
Balenie	1 pc(s).
Netto hmotnosť	50 kg
Brutto hmotnosť	52,66 kg
PCF per pack (cradle-to-gate)	208,6 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Číslo colnej sadzby	94032080
ETIM 9	EC002500
ETIM 8	EC002500
ECLASS 8.0	27180101
Popis výrobku	AX nástenná skriňa, 3-dielna, ŠxVxH 600x1012x573 mm, 21 U, bočnica: uzavretá prírubová doska hore a dole, s komfortnou rukoväťou

# Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------

# Approvals

---

Explanations

Declaration of conformity