


# Rittal – The System.

Faster – better – everywhere.

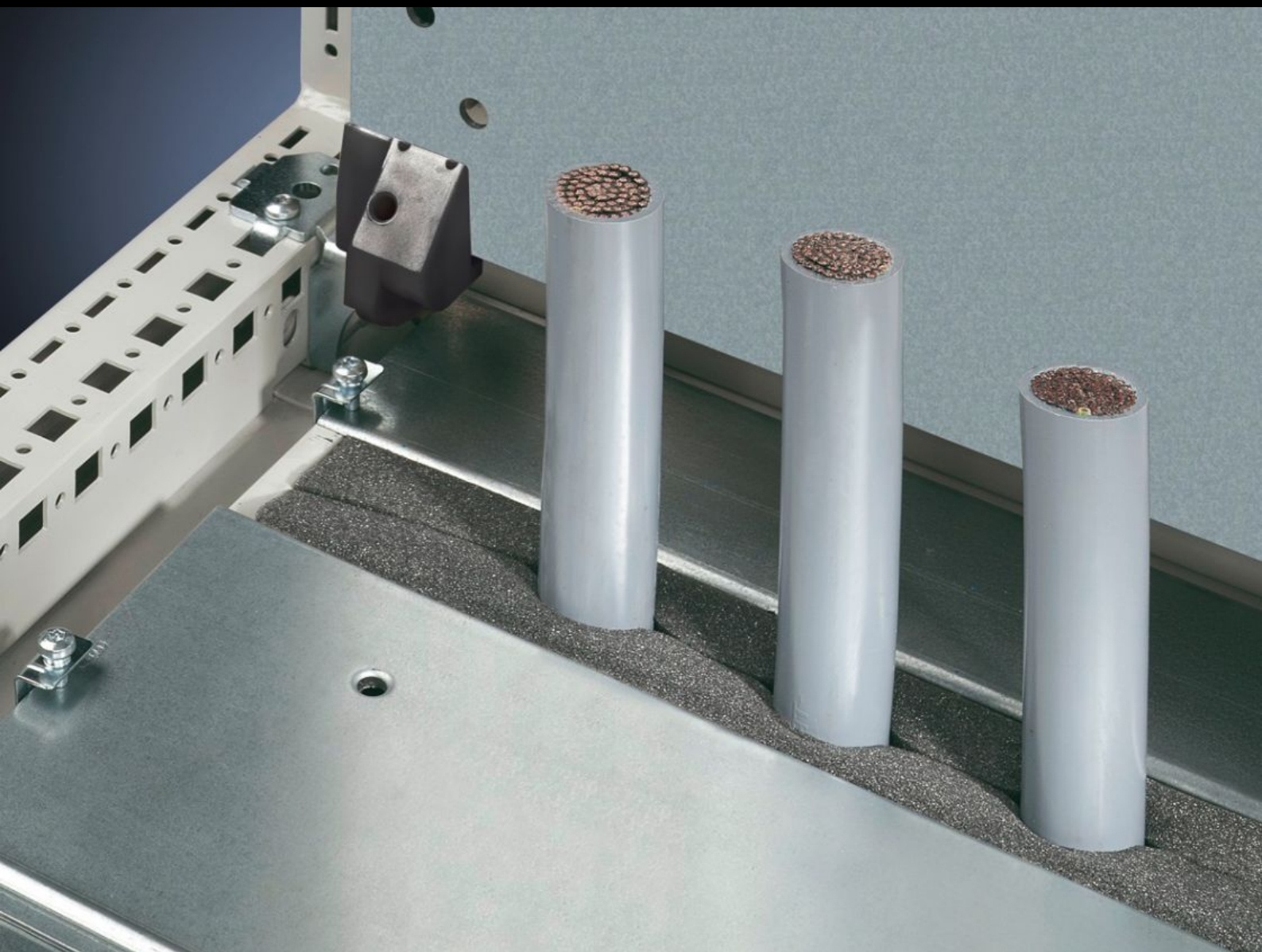

## SZ 2573.000

## Elastický upínací profil

State: 23.5.2026 (Source: [rittal.com/sk-sk](http://rittal.com/sk-sk))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2573.000 - Elastický upínací profil

For sealing the cable entry between the gland plates, particularly suitable for identical cable cross-sections.

## Features

Obj. č.	SZ 2573.000
Materiál	Polyuretánová penová hmota Prierez: 30 x 30 mm
Dĺžka	3 m
Vhodné pre	Typ skrine: VX Typ skrine: TS Typ skrine: TP
Stupeň krytia IP podľa normy IEC 60 529	IP 55 if installed correctly
Balenie	1 pc(s).
Netto hmotnosť	0,11 kg
Brutto hmotnosť	0,133 kg
Číslo colnej sadzby	40169997
ETIM 9	EC002625
ETIM 8	EC002625
ECLASS 8.0	27189234
Popis výrobku	SZ elastický upínací profil, D: 3000 mm