


Rittal – The System.

Faster – better – everywhere.

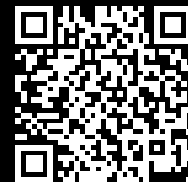

SK 3341.115

Zásuvné a tlačné ventilátory pre 482,6 mm (19")

State: 23.5.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3341.115 - Zásuvné a tlačné ventilátory pre 482,6 mm (19") Množstvo vzduchu 320–480 m³/h

Rack-mounted fan for direct installation in the 482.6 mm (19") level. Installation allows air to circulate permanently inside the enclosure, thus preventing the formation of hot spots.

Features

Obj. č.	SK 3341.115
Farba	RAL 7035
Rozsah dodávky	Kompletné zariadenie pripravené na okamžité pripojenie a použitie Vrátane svorkovnice a upevňovacieho materiálu
Aerodynamický výkon (pri voľnom prúde vzduchu)	480 m ³ /h
Menovité prevádzkové napätie	115 V, 1~, 50 Hz/60 Hz 110 V (DC)
Menovitý prúd max.	Pri 50 Hz: 0,69 A Pri 60 Hz: 0,69 A
Predradené istenie	Istič/tavná poistka: 6 A
Rozmery	Šírka: 482,6 mm Výška: 44 mm Hĺbka: 200 mm
Osová vzdialenosť ventilátorov	85 mm
Počet ventilátorov	3
Hladina akustického tlaku	Pri 50 Hz: 52 dB(A)
Rozsah prevádzkových teplôt	-10 °C...55 °C
Balenie	1 pc(s).
Netto hmotnosť	2 kg
Brutto hmotnosť	2,74 kg
Číslo colnej sadzby	84145915
ETIM 9	EC000320

Features

ETIM 8	EC000320
ECLASS 8.0	27180716
Popis výrobku	SK zásuvný ventilátor, pre 482,6 mm (19"), 480 m ³ /h, 115 V, 1~, 50/60 Hz, ŠxVxH: 482,6 x 44 x 200 mm

Approvals

Approvals	UR + C-UR (recognized) VDE
Explanations	Declaration of conformity
