


Rittal – The System.

Faster – better – everywhere.

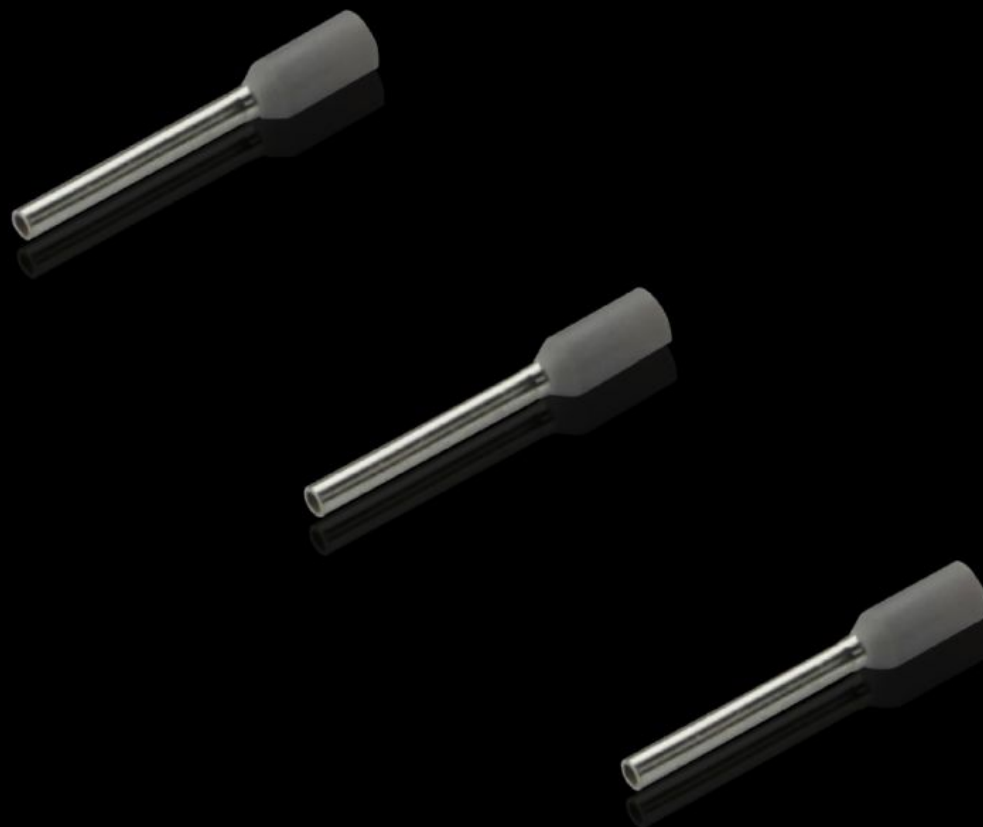

AS 4050.752

Dutinky

State: 4.6.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.752 - Dutinky voľné

With plastic collar.

Features

Obj. č.	AS 4050.752
Technické údaje	Teplotne odolné do 105 °C
Materiál	E-Cu, galvanicky pocínované Plastový lem: polypropylén
Farba	šedá
Dĺžka	8 mm
Prierez	26
Vnútorň priemer	1,5 mm
Farebné značenie Rittal	Yes
Pre prierez	0,14 mm ²
Poznámka	Certifikácia UL v spojení so zodpovedajúcimi nástrojmi, napr. krimpovacími strojmi. Pre individuálne poradenstvo kontaktujte prosím odborného poradcu spoločnosti Rittal.
Normy	AEH DIN 46228
Spôsob dodania	Loose
Balenie	500 pc(s).
Netto hmotnosť	0,5 kg
Číslo colnej sadzby	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Popis výrobku	Dutinky na ručnú montáž, 0,14 mm ² , AWG 26, 8 mm, sivé, voľné, 500 kusov

Approvals

Approvals

UL + C-UL (listed)

UR