


Rittal – The System.

Faster – better – everywhere.

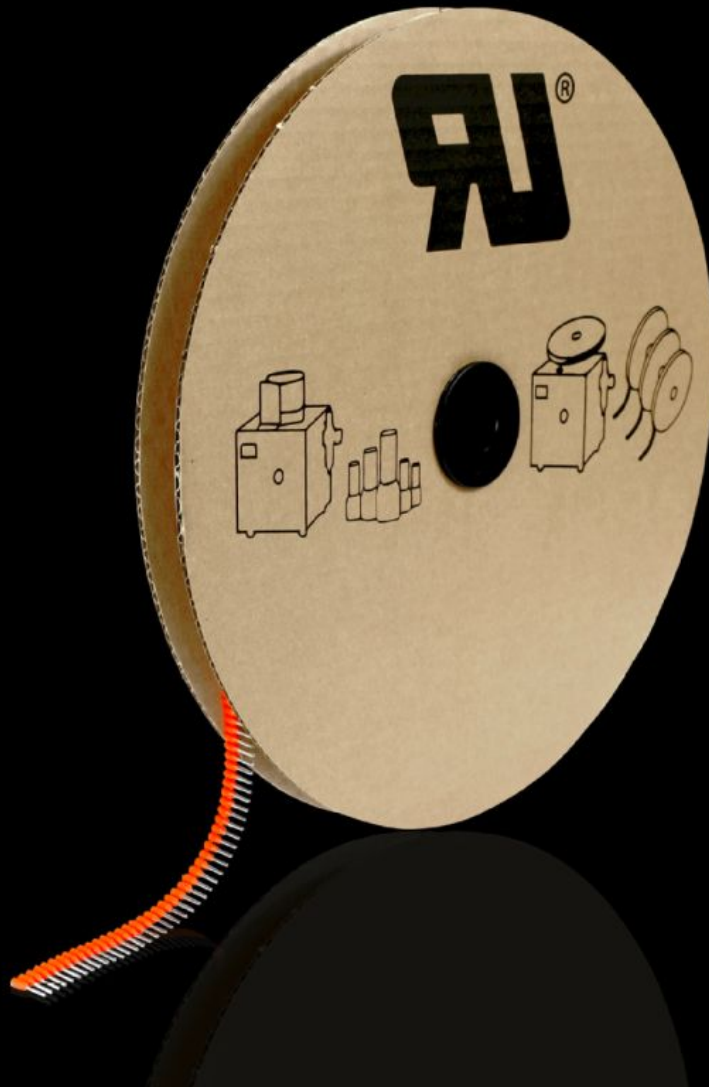

AS 4051.597

Dutinky

State: 23.5.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.597 - Dutinky na páske

With plastic collar.

Features

Obj. č.	AS 4051.597
Technické údaje	Teplotne odolné do 105 °C
Materiál	E-Cu, galvanicky pocínované Plastový lem: polypropylén
Farba	oranžová
Dĺžka	8 mm
Prierez	20
Vnútorň priemer	2,6 mm
Farebné značenie Rittal	Yes
Pre prierez	0,5 mm ²
Poznámka	Certifikácia UL v spojení so zodpovedajúcimi nástrojmi, napr. krimpovacími strojmi.
Normy	AEH DIN 46228
Spôsob dodania	Taped
Balenie	5 000 pc(s).
Netto hmotnosť	5 kg
Brutto hmotnosť	0,536 kg
Číslo colnej sadzby	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Popis výrobku	Dutinky pre krimpovacie stroje, 0,5 mm ² , AWG 20, 8 mm, oranžové, na páske, 5000 kusov

Approvals

Approvals

UL + C-UL (listed)

UR