

# Rittal – The System.

Faster – better – everywhere.



## AS 4052.018 Skrutkovače

State: 28.5.2026 (Source: [rittal.com/sk-sk](http://rittal.com/sk-sk))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4052.018 - Skrutkovače neizolovaný

Ergonomic screwdriver which adapts perfectly to the hand, thereby minimising the force required.

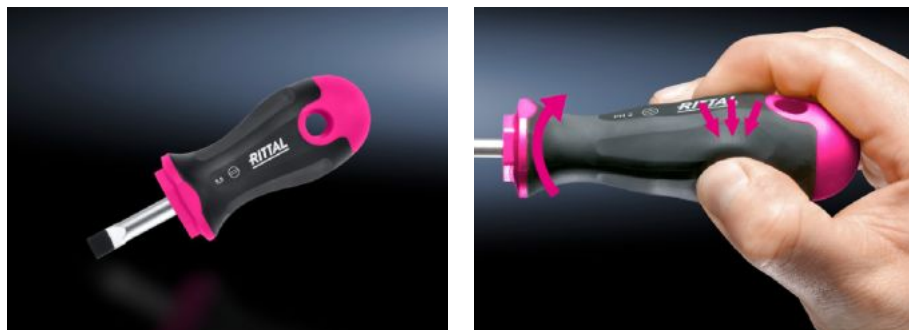

## Features

Obj. č.	AS 4052.018
Prevedenie	pre skrutky s jednou drážkou
Výhody	Hlava rukoväte s ochranou proti skotúľaniu a jasným označením typu skrutkovača Na čierne morená špička hrotu pre zachovanie presnosti a lícovania Optimálne uchopenie rukoväte umožňujúce vyšší krútiaci moment a dlhšiu prácu bez únavy
Materiál	Hrot: zliatina chrómu, molybdénu a vanádu Jadro rukoväte: tvrdý plast Telo rukoväte: elastický, vysoko flexibilný plast
Farba	Rukoväť: antracitová a Rittal Power Pink
Ø hrotu	5 mm
Dĺžka hrotu	25 mm
Hrot (šírka x hrúbka)	5,5 x 1 mm
Typ hrotu	SL
Priemer rukoväte	21 mm
Dĺžka rukoväte	60 mm
Balenie	1 pc(s).
Netto hmotnosť	0,03 kg

# Features

Brutto hmotnosť	0,036 kg
Číslo colnej sadzby	82054000
ETIM 9	EC000144
ETIM 8	EC000158
ECLASS 8.0	21040406
Popis výrobku	Skrutkovač, neizolovaný, hrot: SL 5,5 x 1 mm, s krátkou čepel'ou