


Rittal – The System.

Faster – better – everywhere.

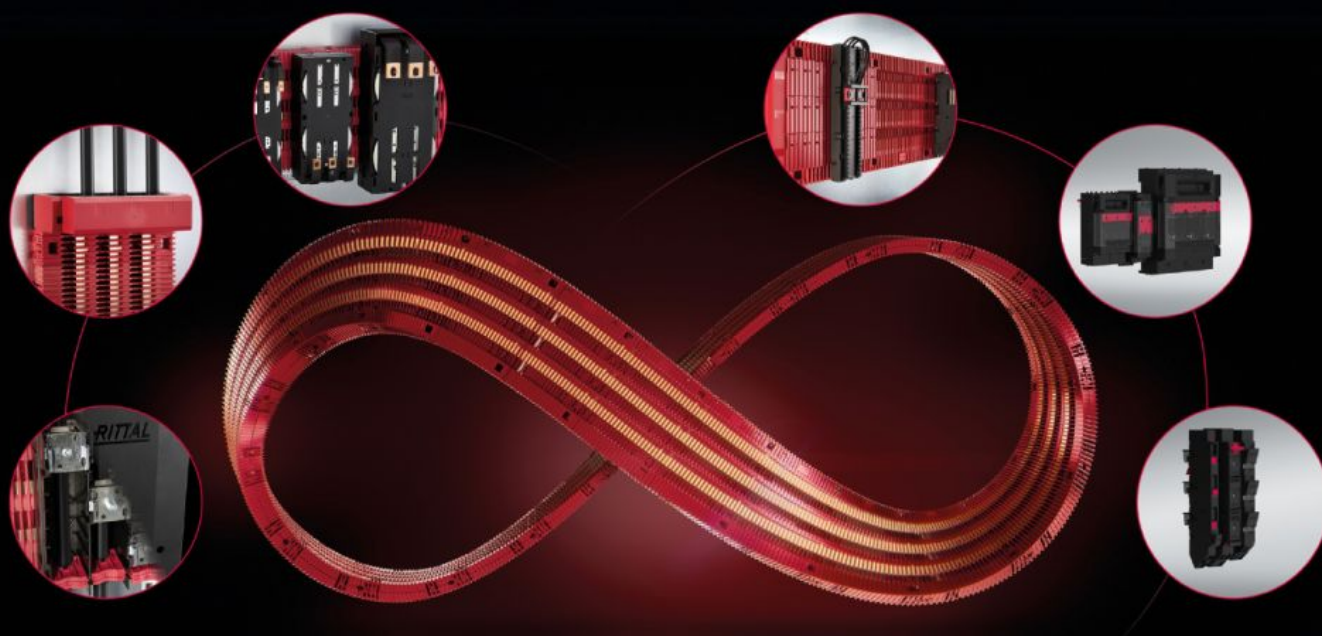

RX 9360.513

RiLineX Circuit-breaker component adaptor

State: 3.8.2025 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.513 - RiLineX Circuit-breaker component adaptor

CB component adaptors for the RiLineX busbar platform in widths 81 to 140 mm. For mounting moulded-case circuit-breakers (MCCBs). Products are available in two variants: An "Easy-Fix" variant for user-friendly external mounting of switches from all standard manufacturers, and a "Universal" variant with U nuts for maximum flexibility.

Features

Obj. č.	RX 9360.513
Provedení	Easy Fix
Materiál	Polyamid (PA 6) Chování při požáru dle UL 94
Barva	RAL 9005 RAL 35745
Jmenovitý proud max.	250 A
Jmenovitý proud (UL)	210 A
Jmenovité rázové napětí Uimp	12 kV
Jmenovité napětí	690 V AC 690 V DC 600 V AC (UL)
Rated insulation voltage	1 000 V
Třída přepětí	4
Stupeň znečištění	3
Počet pólů	3 póly
Vývod vodičů	nahoře
Způsob (elektrického) připojení	Šroub M8
Vhodné pro přípojnícový systém	RiLineX RiLine60
Frekvence základního kmitání	50...60 Hz
Vlhkost vzduchu (nekondenzující)	10...90 %

Features

Vhodné pro přípojnice	15 x 5/10
	20 x 5/10
	30 x 5/10
Rozsah provozních teplot	-25 °C...55 °C
Rozsah skladovacích teplot	-25 °C...75 °C
Rozměry	Šířka: 105 mm
	Výška: 252 mm
	Hloubka: 63 mm
Balení	1 ks

Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------