

Rittal – The System.

Faster – better – everywhere.



RX 9360.600

RiLineX CB component adaptor

State: 23.5.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.600 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. Version for cable outlet at the bottom.

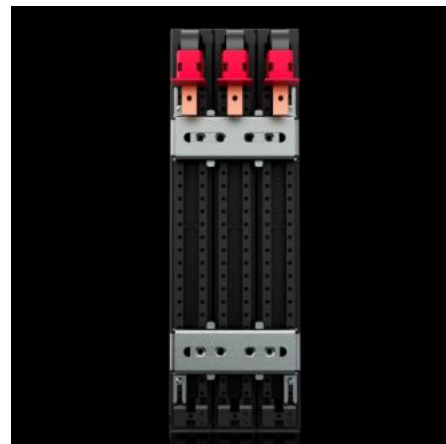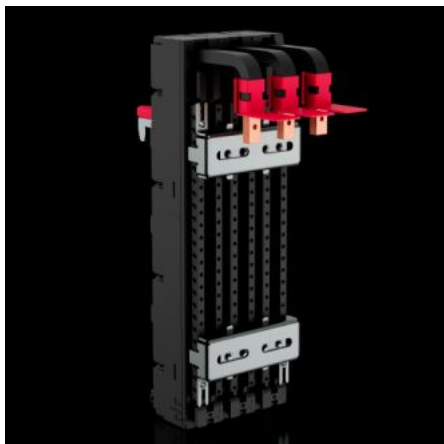

Features

Obj. č.	RX 9360.600
Prevedenie	univerzálna
Výhody	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Materiál	Polyamid (PA 6) Ochrana proti požiaru zodpovedá UL 94
Farba	RAL 9005 RAL 35745
Rozsah dodávky	3 connection space covers
Stupeň krytia IP podľa normy IEC 60 529	IP 2XB
Menovité rázové napätie Uimp	8 kV

Features

Rated voltage	690 V AC 690 V DC 600 V AC (UL)
Rated insulation voltage Ui	1 000 V
Stupeň znečistenia	3
Počet pólov	3-pole
Vývod vodičov	Bottom
Prierez	9 mm ² 6 mm ²
Vhodné pre výrobcov (typ)	Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor.
Vhodné pre prípojnicový systém	RiLineX RiLine60
Frekvencia základného kmitania	50...60 Hz
Vlhkosť vzduchu (nekondenzujúca)	10...90 %
Vhodné pre prípojnice	15 x 5/10 20 x 5/10 30 x 5/10
Rozsah prevádzkových teplôt	-25 °C...55 °C
Rozsah skladovacích teplôt	-25 °C...75 °C
Rozmery	Šírka: 81,9 mm Výška: 251,4 mm Hĺbka: 50,8 mm
Balenie	1 pc(s).
Netto hmotnosť	0,92 kg
Brutto hmotnosť	1,22 kg
Podiel medi (kg / ks)	0,375
PCF per pack (cradle-to-gate)	12,73
Číslo colnej sadzby	85369095
ETIM 9	EC001531

Features

Popis výrobku

RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting. Version for cable outlet at the bottom.

Approvals

Approvals

UL + C-UL (listed)

Explanations

Declaration of conformity
PCF-declaration