

Rittal – The System.

Faster – better – everywhere.



RX 9360.625

RiLineX CB component adaptor

State: 6.7.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.625 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 400 A) for 60 mm busbar systems. The device width is 145 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. The cable outlet is easily converted to the top or bottom to suit individual requirements.

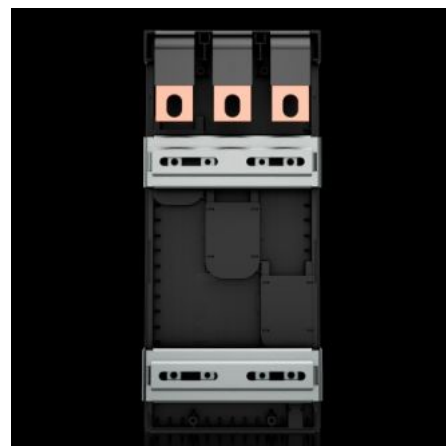

Features

Obj. č.	RX 9360.625
Prevedenie	univerzálna
Výhody	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Materiál	Polyamid (PA 6) Ochrana proti požiaru zodpovedá UL 94
Farba	RAL 9005 RAL 35745
Rozsah dodávky	Including 3 connection space covers, 2 cross members and assembly parts
Stupeň krytia IP podľa normy IEC 60 529	IP 2XB

Features

Menovité rázové napätie Uimp	8 kV
Rated voltage	690 V AC 600 V AC (UL)
Rated insulation voltage Ui	1 000 V
Stupeň znečistenia	3
Počet pólov	3-pole
Vývod vodičov	Top/bottom
Spôsob (elektrického) pripojenia	Screw M10
Prierez	29 mm ² 10 mm ²
Vhodné pre výrobcov (typ)	Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor.
Vhodné pre prípojnicový systém	RiLineX RiLine60
Frekvencia základného kmitania	50...60 Hz
Vlhkosť vzduchu (nekondenzujúca)	10...90 %
Vhodné pre prípojnice	15 x 5/10 20 x 5/10 30 x 5/10
Rozsah prevádzkových teplôt	-25 °C...55 °C
Rozsah skladovacích teplôt	-25 °C...75 °C
Rozmery	Šírka: 145 mm Výška: 325,8 mm Hĺbka: 76,4 mm
Fire load	16,043 MJ/m ²
Balenie	1 pc(s).
Netto hmotnosť	3,6 kg
Brutto hmotnosť	3,8 kg
Podiel medi (kg / ks)	1,652
PCF per pack (cradle-to-gate)	21,11

Features

Číslo colnej sadzby	85369095
ETIM 9	EC001531
Popis výrobku	RiLineX CB component adaptor (3-pole, max. 400 A) for 60 mm busbar systems. The device width is 140 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting. The cable outlet is easily converted to the top or bottom to suit individual requirements.

Approvals

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity PCF-declaration