

# Rittal – The System.

Faster – better – everywhere.



## RX 9360.635

## RiLineX CB component adaptor

State: 22.5.2026 (Source: [rittal.com/sk-sk](http://rittal.com/sk-sk))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

# RX 9360.635 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 630 A) for 60 mm busbar systems. The device width is 145 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. The cable outlet is easily converted to the top or bottom to suit individual requirements.

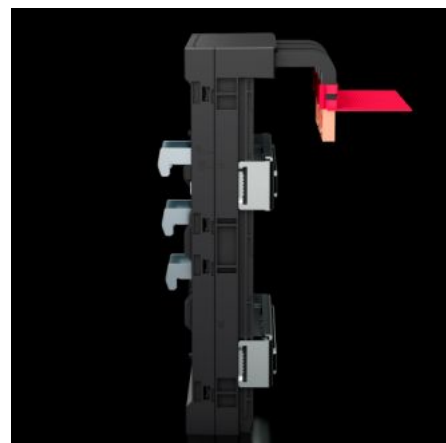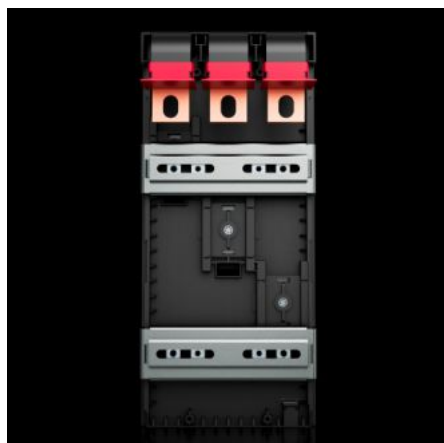

## Features

|   |   |
|---|---|
| Obj. č.                                 | RX 9360.635   |
| Prevedenie                              | univerzálna   |
| Výhody                                  | Direct mounting of moulded-case circuit-breakers (MCCBs) on the board<br>Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm<br>Fast, simple pre-assembly of standard market switch types outside of the enclosure |
| Materiál                                | Polyamid (PA 6)<br>Ochrana proti požiaru zodpovedá UL 94  |
| Farba                                   | RAL 9005<br>RAL 35745   |
| Rozsah dodávky                          | Including 3 connection space covers, 2 cross members and assembly parts   |
| Stupeň krytia IP podľa normy IEC 60 529 | IP 2XB  |

# Features

|                                  |   |
|----------------------------------|---|
| Menovité rázové napätie Uimp     | 8 kV  |
| Rated voltage                    | 690 V AC<br>600 V AC (UL)   |
| Rated insulation voltage Ui      | 1 000 V   |
| Stupeň znečistenia               | 3   |
| Počet pólov                      | 3-pole  |
| Vývod vodičov                    | Top/bottom  |
| Prierez                          | 29 mm <sup>2</sup><br>10 mm <sup>2</sup>  |
| Vhodné pre výrobcov (typ)        | Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor. |
| Vhodné pre prípojnicový systém   | RiLineX<br>RiLine60   |
| Frekvencia základného kmitania   | 50...60 Hz  |
| Vlhkosť vzduchu (nekondenzujúca) | 10...90 %   |
| Vhodné pre prípojnice            | 15 x 5/10<br>20 x 5/10<br>30 x 5/10   |
| Rozsah prevádzkových teplôt      | -25 °C...55 °C  |
| Rozsah skladovacích teplôt       | -25 °C...75 °C  |
| Rozmery                          | Šírka: 145 mm<br>Výška: 325,8 mm<br>Hĺbka: 76,4 mm  |
| Balenie                          | 1 pc(s).  |
| Netto hmotnosť                   | 4,52 kg   |
| Brutto hmotnosť                  | 4,722 kg  |
| Podiel medi (kg / ks)            | 2,64  |
| PCF per pack (cradle-to-gate)    | 28,1  |
| Číslo colnej sadzby              | 85369095  |
| ETIM 9                           | EC001531  |

# Features

---

Popis výrobku

RiLineX CB component adaptor (3-pole, max. 630 A) for 60 mm busbar systems. The device width is 140 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting. The cable outlet is easily converted to the top or bottom to suit individual requirements.

# Approvals

---

Approvals

UL + C-UL (listed)

Explanations

Declaration of conformity  
PCF-declaration