

Rittal – The System.

Faster – better – everywhere.



RX 9360.710 RiLineX component adaptor

State: 7.7.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.710 - RiLineX component adaptor

RiLineX component adaptor (16 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

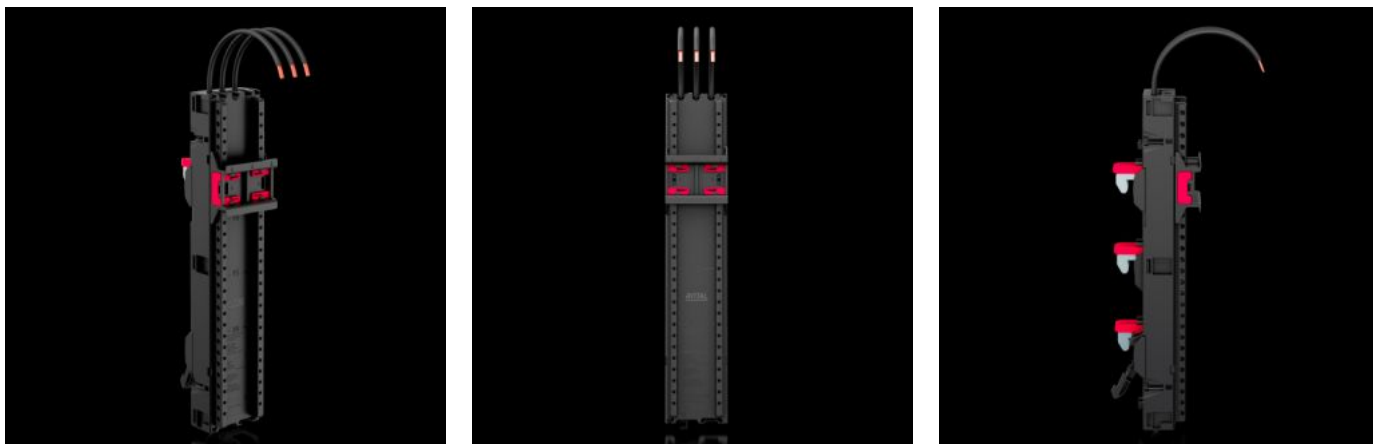

Features

| | |
|---------------------------|--|
| Obj. č. | RX 9360.710 |
| Prevedenie | s prívodným káblom |
| Výhody | For mounting equipment for top hat rail installation, e.g. motor starter Pre-assembled connection cable Simple clip locking for support rails Optional anti-slip guard Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) Jednoduchá montáž Coordinated accessories reduce the number of different items required |
| Materiál | Polyamid (PA 6) Ochrana proti požiaru zodpovedá UL 94 |
| Farba | RAL 9005 RAL 35745 |
| Pripojovacie vodiče (AWG) | AWG 14 |
| Menovitý prúd (max.) | 16 A |

Features

| | |
|--|--|
| Rated current of round conductor | 16 A |
| Rated current of round conductor (UL) | 16 A |
| Elektrické parametre UL (SCCR) | 5 kA - 600 V, RMS 100 kA - 600 V, Fuse Class RK5 max. 30 A, JDDZ/7 65 kA - 480 V, Combination Motor Controller max. 16 A, NKJH/7 30 kA - 600 V, Combination Motor Controller max. 12.5 A, NKJH/7 65 kA - 480 V, Combination Motor Controller max. 40 A, NKJH/7 50 kA - 480 V, circuit breaker max. 22 A, DIVQ/7 |
| Vývod vodičov | Bottom |
| Pre prípojnicové systémy s rozstupom | 60 mm |
| Dĺžka prívodného kábla | 150 mm |
| Počet pólov | 3-pole |
| Vhodné pre prípojnicový systém | RiLineX RiLine60 |
| Rozmery | Šírka: 45 mm Výška: 239,4 mm Hĺbka: 36,2 mm |
| Počet nosných líšt / výška | 1 / 10 mm |
| Vhodné pre prípojnice | 15 x 5/10 20 x 5/10 30 x 5/10 |
| Rated voltage | 690 V AC 600 V AC (UL) 600 V DC (UL) |
| Stupeň znečistenia | 3 |
| Normy | IEC 61 439-1/-2 UL 508 |
| Menovité rázové napätie U _{imp} | 8 kV |
| Rated insulation voltage U _i | 1 000 V |

Features

| | |
|---|--|
| Stupeň krytia IP podľa normy IEC 60 529 | IP 2XB |
| Maximum operating air humidity | 90 % |
| Rozsah prevádzkových teplôt | -5 °C...55 °C |
| Rozsah skladovacích teplôt | -25 °C...75 °C |
| Vlhkosť vzduchu (nekondenzujúca) | 10...90 % |
| Fire load | 3,419 MJ/m ² |
| Balenie | 4 pc(s). |
| Netto hmotnosť | 1,2 kg |
| Brutto hmotnosť | 1,35 kg |
| Podiel medi (kg / ks) | 0,108 |
| PCF per pack (cradle-to-gate) | 8,51 |
| Číslo colnej sadzby | 85369095 |
| ETIM 9 | EC001531 |
| Popis výrobku | RiLineX component adaptor (16 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment. |

Approvals

| | |
|--------------|--|
| Approvals | UL + C-UL (listed) |
| Explanations | Declaration of conformity PCF-declaration |