

# Rittal – The System.

Faster – better – everywhere.



## RX 9360.760

## RiLineX component adaptor

State: 6.7.2026 (Source: [rittal.com/sk-sk](http://rittal.com/sk-sk))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.760 - RiLineX component adaptor

RiLineX component adaptor (65 A, 3-pole, including connection cables) in width 54 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

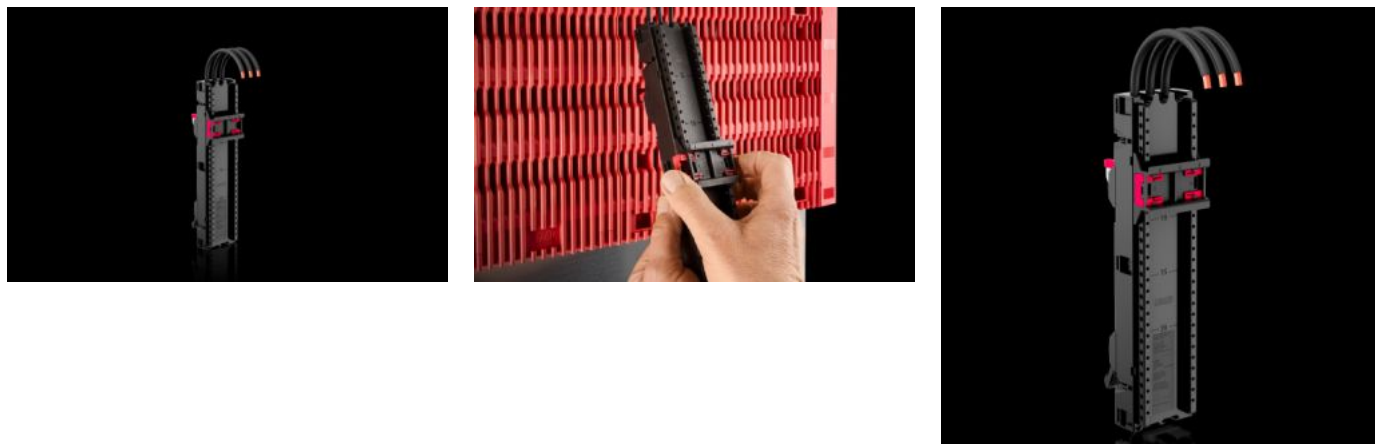

## Features

Obj. č.	RX 9360.760
Prevedenie	s prívodným káblom
Výhody	For mounting equipment for top hat rail installation, e.g. motor starter Pre-assembled connection cable Simple clip locking for support rails Optional anti-slip guard Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) Jednoduchá montáž Coordinated accessories reduce the number of different items required
Materiál	Polyamid (PA 6) Ochrana proti požiaru zodpovedá UL 94
Farba	RAL 9005 RAL 35745
Pripojovacie vodiče (AWG)	AWG 6
Menovitý prúd (max.)	65 A

# Features

Rated current of round conductor	65 A
Rated current of round conductor (UL)	65 A
Elektrické parametre UL (SCCR)	100 kA - 600 V, Fuse Class RK5 max. 60 A, JDDZ/7 20 kA - 600 V, circuit breaker max. 60 A, DIVQ/7 65 kA - 480 V, Combination Motor Controller max. 52 A, NKJH/7
Vývod vodičov	Bottom
Pre prípojnicové systémy s rozstupom	60 mm
Dĺžka prívodného kábla	130 mm
Počet pólov	3-pole
Vhodné pre prípojnicový systém	RiLineX RiLine60
Rozmery	Šírka: 54 mm Výška: 239,4 mm Hĺbka: 36,2 mm
Počet nosných líšt / výška	1 / 10 mm
Vhodné pre prípojnice	15 x 5/10 20 x 5/10 30 x 5/10
Rated voltage	690 V AC 600 V AC (UL) 600 V DC (UL)
Stupeň znečistenia	3
Normy	IEC 61 439-1/-2 UL 508
Menovité rázové napätie Uimp	8 kV
Rated insulation voltage Ui	1 000 V
Stupeň krytia IP podľa normy IEC 60 529	IP 2XB
Maximum operating air humidity	90 %

# Features

Rozsah prevádzkových teplôt	-5 °C...55 °C
Rozsah skladovacích teplôt	-25 °C...75 °C
Vlhkosť vzduchu (nekondenzujúca)	10...90 %
Fire load	3,763 MJ/m <sup>2</sup>
Balenie	4 pc(s).
Netto hmotnosť	1,84 kg
Brutto hmotnosť	1,883 kg
Podiel medi (kg / ks)	0,145
PCF per pack (cradle-to-gate)	13,53
Číslo colnej sadzby	85369095
ETIM 9	EC001531
Popis výrobku	RiLineX component adaptor (65 A, 3-pole, including connection cables) in width 54 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

# Approvals

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity PCF-declaration