

Rittal – The System.

Faster – better – everywhere.



RX 9364.004 RiLineX fuse holder

State: 1.6.2026 (Source: rittal.com/sk-sk)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9364.004 - RiLineX fuse holder

Compact RiLineX class CC fuse holder for 60 mm busbar systems. For class CC cylindrical fuse (30 A) with optical LED fuse monitoring. For reliable contact of cylindrical fuses, the device has special fuse holders that are lockable in the open state and sealable in the closed state. Spring terminal blocks up to 6 mm² at an angle of 45° enable easier conductor connection. The device is suitable for tool-free snap-on mounting with semi-automatic busbar adjustment for 5 and 10 mm. Includes electronic fuse monitoring.

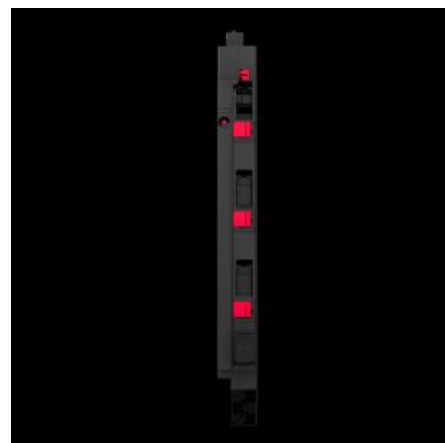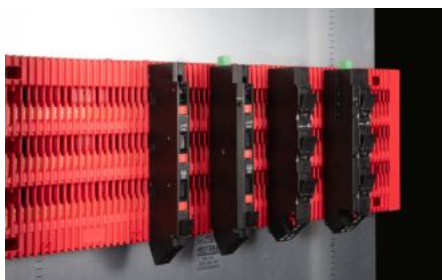

Features

Obj. č.	RX 9364.004
Výhody	Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) For Class CC fuse to UL 248-4 UL-listed, approved to UL 4248 Innovative swivel mechanism, selective replacement of individual fuse inserts supported Readily accessible push-in connections in the lower section Fuse removal tools included with the supply Can be locked and prepared for a lead seal s elektronickou indikáciou stavu poistiek (ESÜ)
Materiál	Polyamid (PA 6) Správanie sa pri požari podľa UL 94-V0
General colour	RAL 9005 RAL 35745
Menovitý prúd (max.)	30 A

Features

Spôsob (elektrického) pripojenia	Spring terminal
Menovité prevádzkové napätie	600 V AC
Elektrické parametre UL (SCCR)	200 kA - 600 V, Fuse Class CC max. 30 A, JDDZ/7
Počet pólov	3-pole
Rozmery	Šírka: 27 mm Výška: 263 mm Hĺbka: 123,5 mm
Pripojenie okrúhlych vodičov, jemne lankových s lisovacou dutinkou	1,5 - 6 mm ²
Vhodné pre prípojnice	15 x 5/10 20 x 5/10 30 x 5/10
Poistkové vložky	Class CC
Pre typ poistky (triedu)	Fuse Class CC
Balenie	4 pc(s).
Netto hmotnosť	1,2 kg
Brutto hmotnosť	1,406 kg
Číslo colnej sadzby	85369095

Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------