

Rittal – The System.

Faster – better – everywhere.



IT 7100.120 OCP ORV3 rack

Durum: 03.05.2025 (Kaynak: rittal.com/tr-tr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



IT 7100.120 - OCP ORV3 rack

OCP is an ambitious international community that aims to simplify and optimise IT infrastructure. The Rittal OCP ORV3 rack is OCP accepted and ready for immediate use. Simple modifications and enhancements can be made as and when required, thanks to the range of accessories. The OCP ORV3 rack can also accommodate a Direct Liquid Cooling (DLC) solution. Take your efficiency and performance density to a whole new level with this rack.

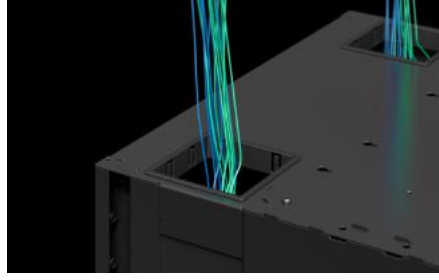

Özellikleri

Model No.	IT 7100.120
Dizayn	Open frame Prepared for cable entry in roof and base Cable routing at the front, across the full height
Fayda	OCP ORV3 rack open on all sides and in line with Standard V3 of the OCP Community Prepared to accommodate 21" OCP components and direct contact on the busbar Rapid construction and service thanks to click-in fitting of the IT and IT OCP Power rail system End-to-end cable management in front rack over full height Ideal for high-performance computing and AI technology thanks to being ready for Direct Liquid Cooling solutions that are designed to dissipate the thermal load generated in the rack 1400 kg'a kadar yüklenebilir Integrated heavy-duty castors make transportation easier and ensure ease of handling in the data centre
Teknik özellikler	Rated operating voltage: 48 V DC / power consumption 18 kW
Malzeme	Çelik sac
Yüzey	Daldırma astar boyalı, dıştan toz kaplamalı

Özellikleri

Renk	RAL 9005
Teslimat kapsamı	OCP ORV3 rack OCP busbar for max. 48 DC/18 kW 2 bracing struts, pre-assembled Levelling feet, pre-assembled 4 castors (freely rotating) Modüler genişleme contası Hava izolasyon plakası
Ölçüler	Genişlik: 600 mm Yükseklik: 2.286 mm Derinlik: 1.068 mm
Yükseklik birimleri	44 OU
Taşıma kapasitesi	14.000 N
Ana malzeme	Çelik sac
Paketteki adet	1 adet
Net ağırlık	172
Brüt ağırlık	200
Gümrük tarifesi numarası	94032080
EAN	4028177997738
ETIM 9	EC002499
ETIM 8	EC002499
ECLASS 8.0	27180207

Onaylar

Onaylar	IEC CB UL + C-UL (listed)
Açıklamalar	Uygunluk bildirimi