


# Rittal – The System.

Faster – better – everywhere.

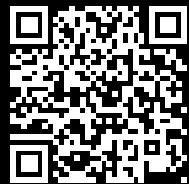

## SZ 2500.470

### Door-operated switch

State: 29.01.2026 (Source: [ittal.com/ua-en](https://www.ittal.com/ua-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2500.470 - Door-operated switch for LED system light

For simple, time-saving connection of the LED system light.

## Features

Model No.	SZ 2500.470
Design	With connection cable
Product description	For time-saving and simple installation of the LED system light.
Colour	Black
Supply includes	Assembly parts
Cross-section	0.75 mm <sup>2</sup>
Length	800 mm
AWG	AWG 18
Standards	Power supply cords: CYJV2 Door-operated switch: NKCR
Dimensions	Width: 31 mm Height: 78 mm Depth: 30 mm Length: 800 mm
Electrical connection	2.5 A
Rated operating voltage	230 V (AC) 24 V (DC)
Packs of	1 pc(s).
Net weight	0.1
Gross weight	0.12
Customs tariff number	85365019
EAN	4028177809154
E-Number Sweden	E3465314
ETIM 9	EC002626

# Features

---

ETIM 8 EC002626

---

ECLASS 8.0 27189266

# Approvals

---

Approvals CQC  
CQC-CCC  
UL + C-UL (listed)

---

Explanations Declaration of conformity  
Declaration of conformity UK