


Rittal – The System.

Faster – better – everywhere.

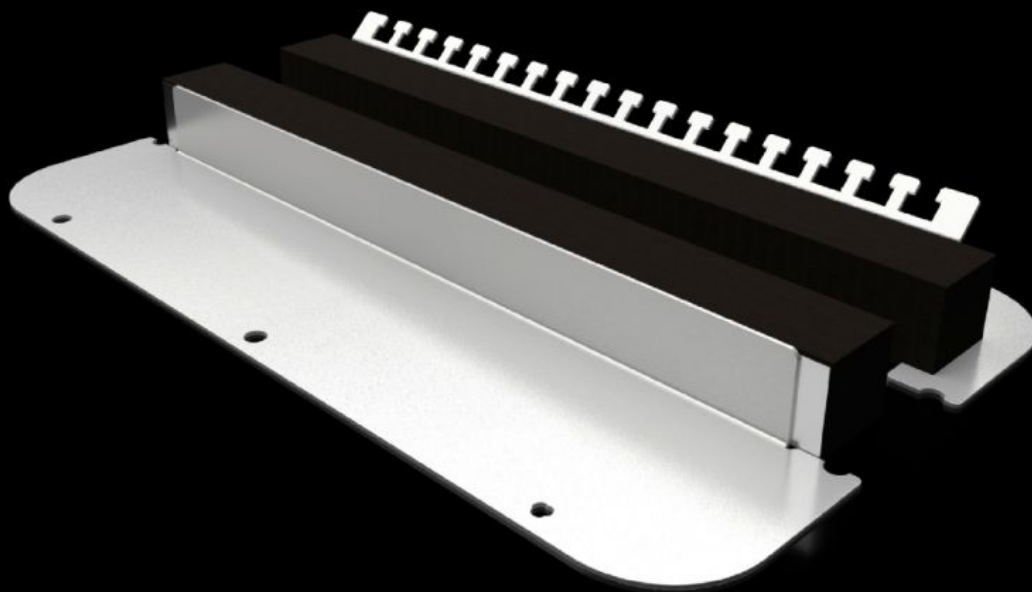

SZ 2562.450

**Two-part gland plate with foam
rubber cable clamp strip**

State: 23.05.2026 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2562.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

Features

| | |
|-----------------------|---|
| Model No. | SZ 2562.450 |
| Design | two-piece |
| Material | Sheet steel |
| Colour | RAL 7035 |
| Supply includes | Assembly parts |
| Note | The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required |
| Dimensions | Width: 339 mm Depth: 149 mm |
| To fit | Enclosure type: AX |
| To fit Model No. | 1031000 1038000 1045000 1077000 1094000 1380000 |
| Gland plate | Size: 2 |
| Packs of | 1 pc(s). |
| Net weight | 0.596 kg |
| Gross weight | 0.796 kg |
| Customs tariff number | 73269098 |

Features

| | |
|--------|----------|
| ETIM 8 | EC000211 |
|--------|----------|

| | |
|------------|----------|
| ECLASS 8.0 | 27142421 |
|------------|----------|

| | |
|---------------------|---|
| Product description | SZ metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD: 339x149 mm, for size 2 gland plates |
|---------------------|---|