


Rittal – The System.

Faster – better – everywhere.

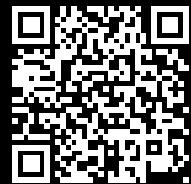

SZ 2566.200

Plastic gland plate, modular

State: 30.01.2026 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2566.200 - Plastic gland plate, modular with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).

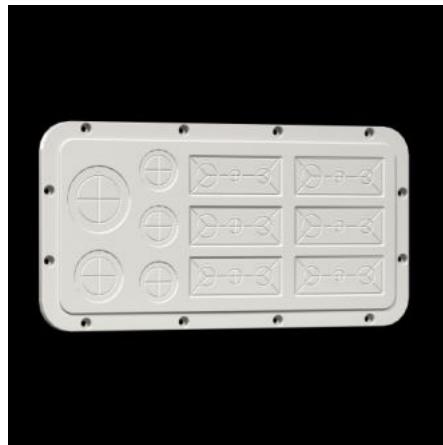

Features

Model No.	SZ 2566.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Colour	RAL 7035
Number of rectangular cutouts information	1 rectangular cut-out can hold 10 small seal inserts
Number of rectangular cutouts	6
Note	The allocation of gland plate sizes is indicated on the relevant enclosures

Features

No. of metric knockouts	4 x M12 5 x M16 5 x M20 4 x M25 1 x M32 1 x M40 1 x M50
Dimensions	Width: 401 mm Depth: 221 mm
To fit	Enclosure type: AX
Gland plate	Size: 6
Operating temperature range	-40 °C...80 °C
Protection category to IEC 60 529	IP 66 if installed correctly
Type rating to UL 50E	Type 1 Type 12
Number knockouts	4 5 5 4 1 1 1
Metric diameter	M12 M16 M20 M25 M32 M40 M50
Packs of	1 pc(s).
Net weight	0.5
Gross weight	0.56
Customs tariff number	39269097
EAN	4028177938441

Features

ETIM 9 EC000211

ETIM 8 EC000211

ECLASS 8.0 27142421

Approvals

Approvals UL + C-UL - FTTA