


Rittal – The System.

Faster – better – everywhere.

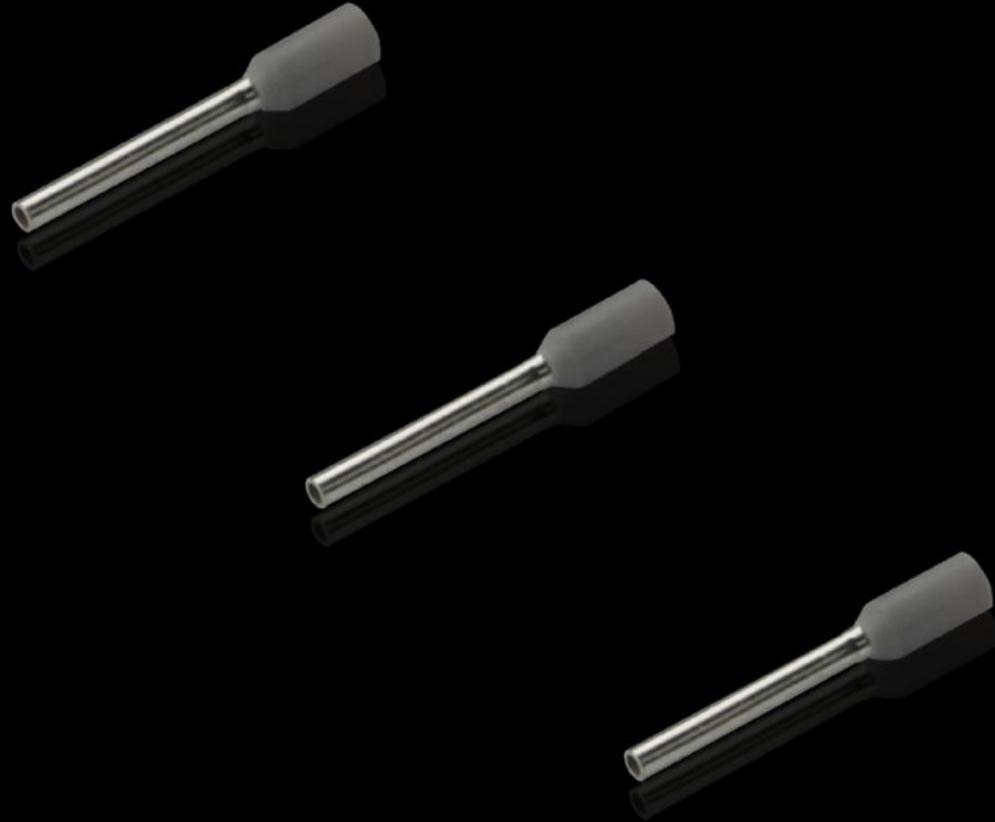

AS 4050.752 Wire end ferrules

State: 28.03.2026 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.752 - Wire end ferrules loose

With plastic collar.

Features

| | |
|--------------------------|---|
| Model No. | AS 4050.752 |
| Product description | With plastic collar. |
| Technical specifications | Heat-resistant to 105 °C |
| Material | E-Cu, galvanic tin-plated Plastic collar: Polypropylene |
| Colour | Grey |
| Length | 8 mm |
| AWG | 26 |
| Internal diameter | 1.5 mm |
| Rittal colour code | Yes |
| For cross-section | 0.14 mm ² |
| Note | UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant. |
| Standards | AEH DIN 46228 |
| Delivery form | Loose |
| Packs of | 500 pc(s). |
| Net weight | 0.5 kg |
| Customs tariff number | 85369010 |
| ETIM 9 | EC000005 |
| ETIM 8 | EC000005 |
| ECLASS 8.0 | 36659290 |
| Product description | Wire end ferrules for manual preassembly, 0.14 mm ² , AWG 26, 8 mm, grey, loosely packed, 500 pc(s). |

Approvals

Approvals

UL + C-UL (listed)

UR