


Rittal – The System.

Faster – better – everywhere.

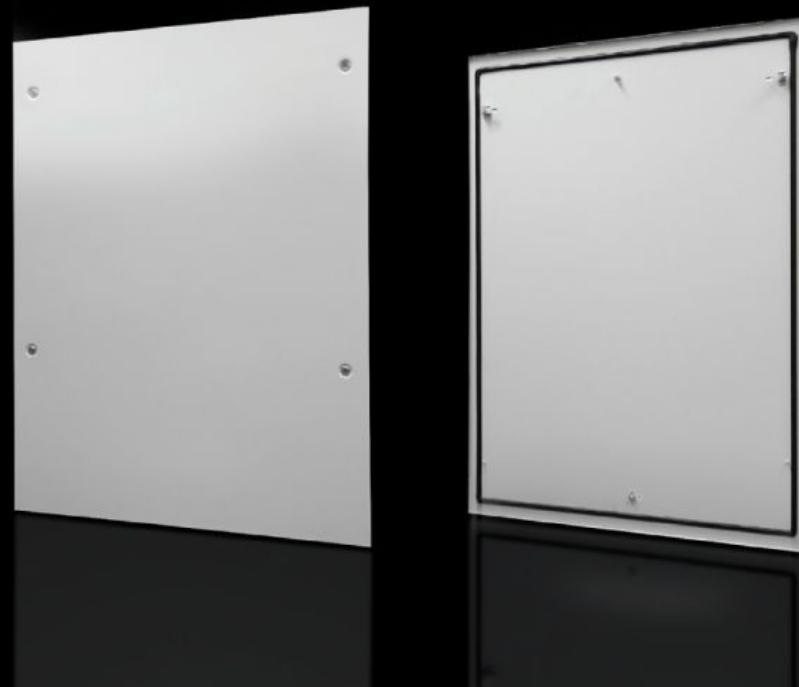

DK 7824.128

Side panel, lockable

State: 01.02.2026 (Source: rittal.com/ua-en)



DK 7824.128 - Side panel, lockable for TS, TS IT

Side panel, lockable, sheet steel, for TS.



Features

Model No.	DK 7824.128
Product description	Simply locate from above. Lock with security lock no. 3524 E. Earthing bolt with contact track.
Material	Sheet steel
Surface finish	Spray-finished
Colour	RAL 7035
Supply includes	2 side panels each with 4 security locks no. 3524 E
To fit	Enclosure type: TS IT TX CableNet TS Height: 1,200 mm Depth: 800 mm
Basic material	Sheet steel
Packs of	2 pc(s).
Net weight	24
Gross weight	25.8
Customs tariff number	94039910
EAN	4028177232235
E-Number Sweden	E7239564

Features

ETIM 9 EC002524

ECLASS 8.0 27182101

Tender text

Side panel, plug-type, for TS

H x D = 1200 x 800 mm, RAL 7035

Side panel fitted with a T-lock.

Material: Sheet steel, spray finished in RAL 7035

For 1200 mm x 800 mm enclosures