


Rittal – The System.

Faster – better – everywhere.

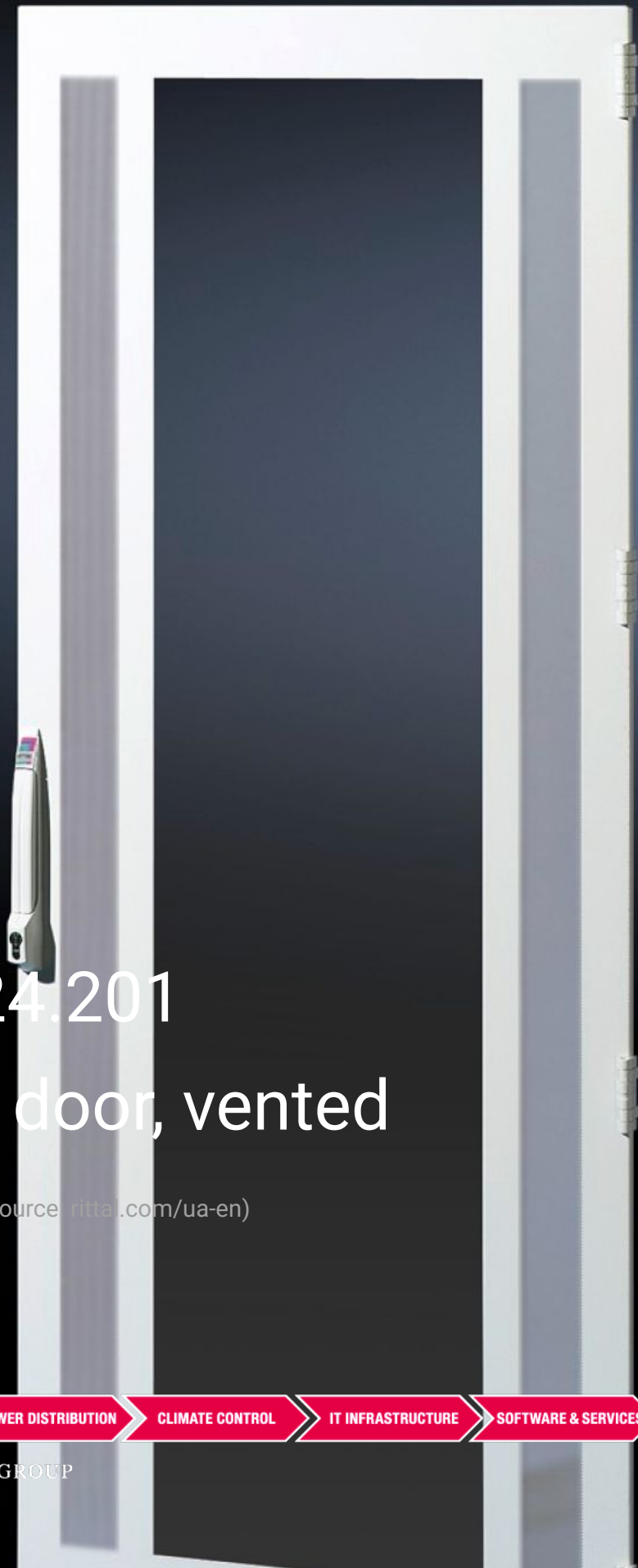

DK 7824.201 Glazed door, vented

State: 05.06.2026 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.201 - Glazed door, vented for TS, TS IT, VX SE

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

Features

| | |
|-----------------------|---|
| Model No. | DK 7824.201 |
| Product description | Surface perforated on both sides with air inlet openings > 78% for optimum air throughput. |
| Material | Door: Sheet steel Viewing window: Single-pane safety glass, 3 mm |
| Surface finish | Powder-coated |
| Colour | RAL 7035 |
| Supply includes | Glazed door, vented Comfort handle for profile half-cylinders with security lock 3524 E 180° hinges (4) Assembly parts |
| Assembly instruction | For TS enclosure suites with sheet steel doors, only the 180° hinge 7824.520 may be used. |
| To fit | Enclosure type: TS TS IT SE Width: 600 mm Height: 2,000 mm |
| Packs of | 1 pc(s). |
| Net weight | 19.38 kg |
| Gross weight | 20.4 kg |
| Customs tariff number | 94039910 |
| ETIM 9 | EC000747 |
| ECLASS 8.0 | 27182204 |
| Product description | DK-TS Glazed door, WxH: 600x2000 mm, Vented |

Tender text

Glazed door, vented, for TS

Glazed door, vented, made from 1.5 mm sheet steel with side slotted surfaces in RAL 7035, with foamed-in seal, 180° hinges, 3 mm thick single-pane safety glass, 4-point latch locking rod, comfort handle with security lock no. 3524 E. A semi-cylinder (40/45 mm) to DIN 18254 may be inserted.

Hinges with captive hinge pins, door hinge may be swapped from right to left without dismantling locking rods. Door opening angle 180°.

Material: Sheet steel

Pane: Safety glass, 3 mm

Colour:

Frame: RAL 7035

Pane: Tinted, parsol grey

Dimensions: For enclosures (WxH): W: 600 mm H: 2000 mm