
 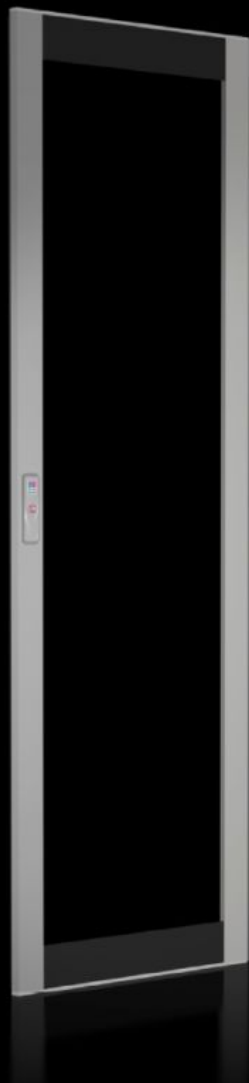


Rittal – The System.

Faster – better – everywhere.



VX 8618.040 Glazed door

State: 13.05.2024 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8618.040 - Glazed door for VX

Instead of a sheet steel door or rear panel.

Features

Model No.	VX 8618.040
Product description	Instead of a sheet steel door or rear panel.
Material	Frame: Extruded aluminium section Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Colour	Frame: RAL 7035 Viewing window (printed mask on the inside): RAL 9005
Supply includes	Glazed door Locking rod with double-bit insert 180° hinges (4)
IK Code	IK08
Note	Lock components for frame 8618.110 are required when mounting instead of the rear panel
Type rating to UL 50E	Type 1, 12
IP protection category to IEC 60529	IP 55
To fit	Enclosure type: VX Width: = 600 mm Height: = 2,200 mm
Packs of	1 pc(s).
Weight/pack	15.4 kg
EAN	4028177920934
ETIM 7.0	EC000747
ECLASS 8.0	27182204

Approvals

Approvals	UL + C-UL (listed)
	UL + C-UL - FTTA
Certificates	Protection category