
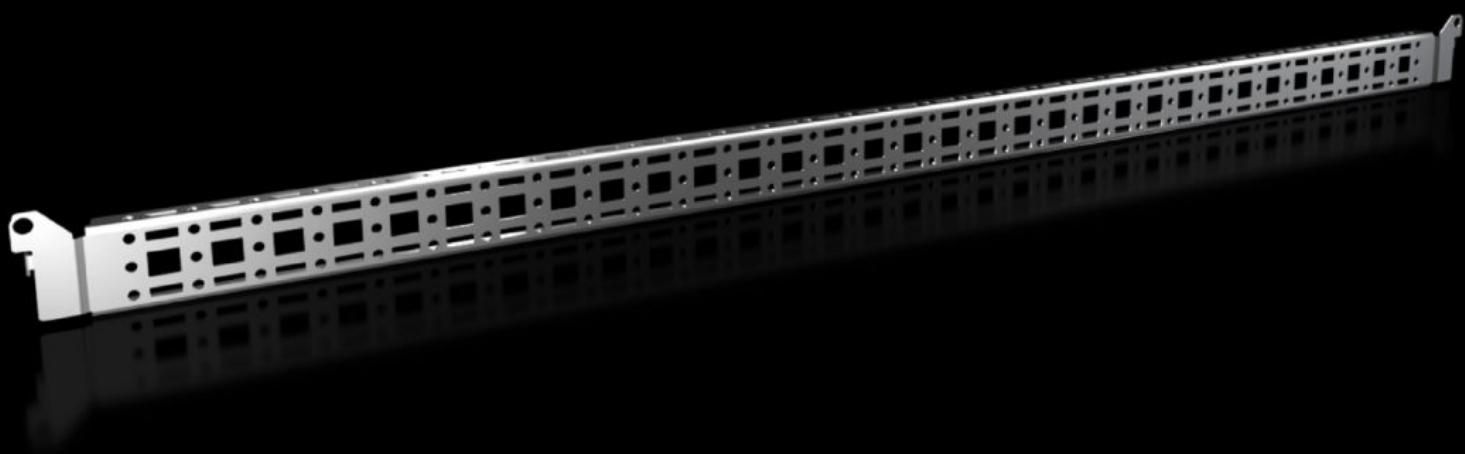


Rittal – The System.

Faster – better – everywhere.

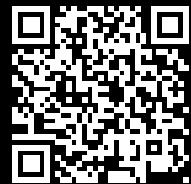

VX 8619.750

Punched section with mounting flange, 14 x 39 mm

State: 01.02.2026 (Source: rittal.com/ua-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL



IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

VX 8619.750 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.

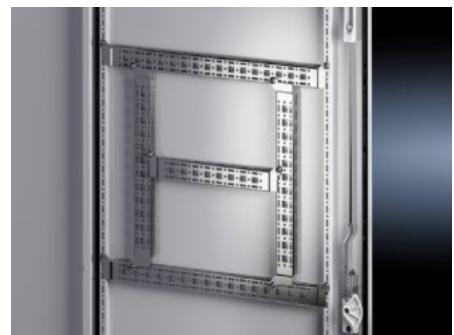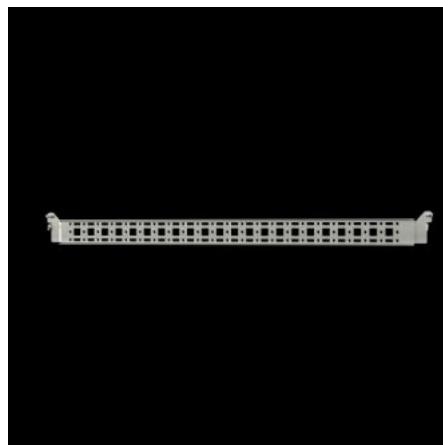

Features

Model No.	VX 8619.750
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	875 mm
To fit door width	1,000 mm
VX SE installation options	In door width 900 mm
AX stainless steel installation options	In enclosure height 1000 mm
Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required

Features

To fit	Enclosure type: VX SE AX stainless steel Suitable for width or height or depth: 1,000 mm
Packs of	4 pc(s).
Net weight	1.776
Gross weight	2.06
Customs tariff number	73269098
EAN	4028177924642
E-Number Sweden	E3465283
ETIM 9	EC002620
ECLASS 8.0	27189234
