


Rittal – The System.

Faster – better – everywhere.

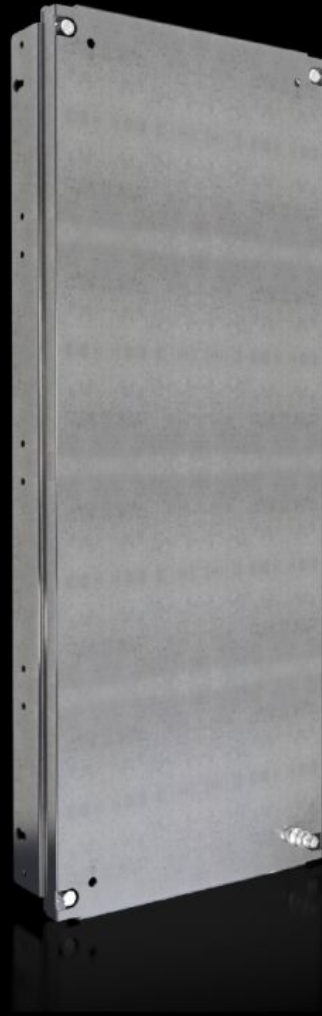

SV 9683.648

Partial mounting plate

State: 02.06.2026 (Source: rittal.com/ua-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9683.648 - Partial mounting plate for compartment side panel

With or without duct, for direct attachment to the functional space side panel.

Features

| | |
|-------------------------------|--|
| Model No. | SV 9683.648 |
| Design | solid |
| Product description | For direct attachment to the compartment side panel for internal compartmentalisation. Universal interior installation with switchgear and controlgear. Creation of additional mounting levels. In combination with compartment dividers and side panel, internal compartmentalisation in accordance with Form 1 to 4 is possible. |
| Material | Sheet steel, 2 mm |
| Surface finish | Zinc-plated |
| Supply includes | Angle brackets and assembly parts |
| For compartment height | 800 mm |
| Dimensions | Width: 302 mm Height: 793 mm |
| To fit | Width: = 400 mm |
| Packs of | 1 pc(s). |
| Net weight | 6.4 kg |
| Gross weight | 6.9 kg |
| PCF per pack (cradle-to-gate) | 26.3 kg CO2 eq (Cat B) |
| Note on PCF category | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number | 94039910 |
| ETIM 9 | EC000213 |
| ECLASS 8.0 | 27400613 |

Features

Product description

SV Partial mounting plate, WH: 302x793 mm, solid, for VX (W: 400 mm)

Approvals

Explanations

Declaration of conformity UK