

**Rittal – The System.**

Faster – better – everywhere.



**SZ 2423.000**

**Spacer**

State: 22/05/2026 (Source: [rittal.com/uae-en](http://rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2423.000 - Spacer for roof plate

To raise the roof for ventilation purposes, in three different heights. Not suitable for crane transportation.

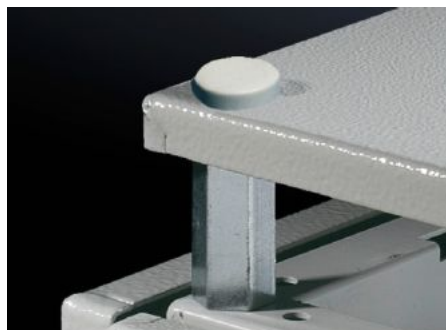

## Features

Model No.	SZ 2423.000
Product description	To raise the roof for ventilation purposes, in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly parts
Assembly instruction	Not suitable for crane transportation
Dimensions	Height: 20 mm
Dimensions	Thread: M12
To fit	Enclosure type: VX TS
Packs of	4 pc(s).
Net weight	0.216 kg
Gross weight	0.255 kg
PCF per pack (cradle-to-gate)	1 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73269098

# Features

---

ETIM 9	EC002625
ETIM 8	EC002625
ECLASS 8.0	27189234
Product description	SZ Spacer, for VX, TS, roof plate, H: 20 mm

---