
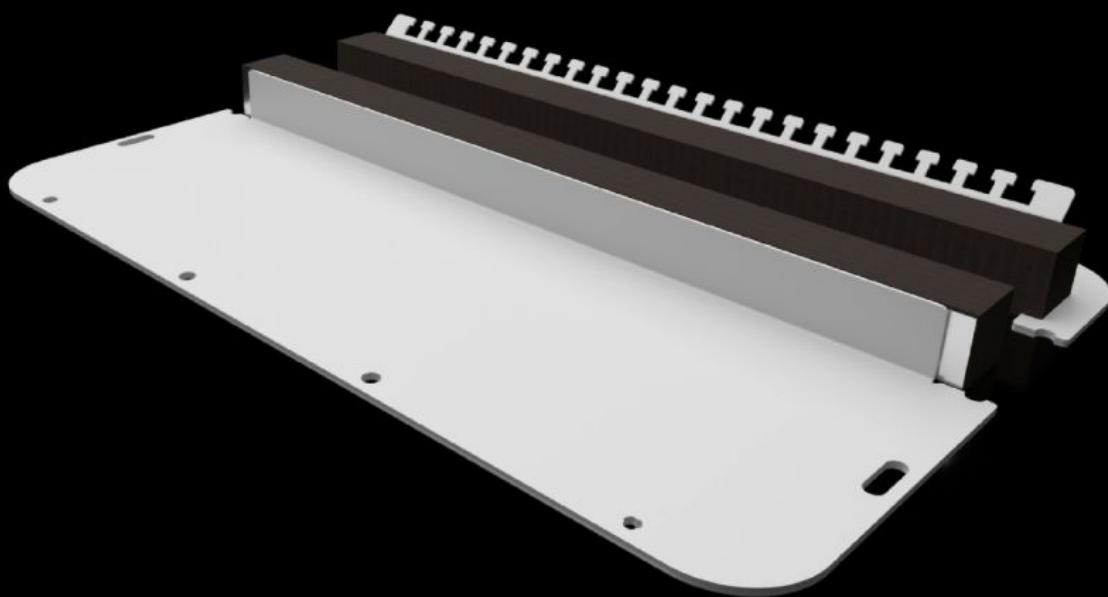


Rittal – The System.

Faster – better – everywhere.

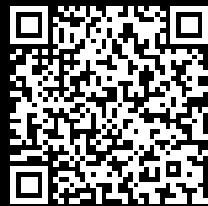

SZ 2567.450

Two-part gland plate with foam
rubber cable clamp strip

State: 16/01/2026 (Source: rittal.com/uae-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

SZ 2567.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

Features

Model No.	SZ 2567.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	<p>The allocation of gland plate sizes is indicated on the relevant enclosures</p> <p>When installing in enclosure width >760 mm, 2 packs are required</p>
Dimensions	<p>Width: 436 mm</p> <p>Depth: 221 mm</p>
To fit	Enclosure type: AX
To fit Model No.	<p>1260.000</p> <p>1339.000</p> <p>1360.000</p> <p>1376.000</p> <p>1059.000</p> <p>1091.000</p> <p>1116.000</p> <p>1261.000</p>
Gland plate	Size: 7
Packs of	1 pc(s).
Net weight	1.4
Gross weight	1.46

Features

PCF per pack (cradle-to-gate)	5.6 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73079100
EAN	4028177973145
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
