
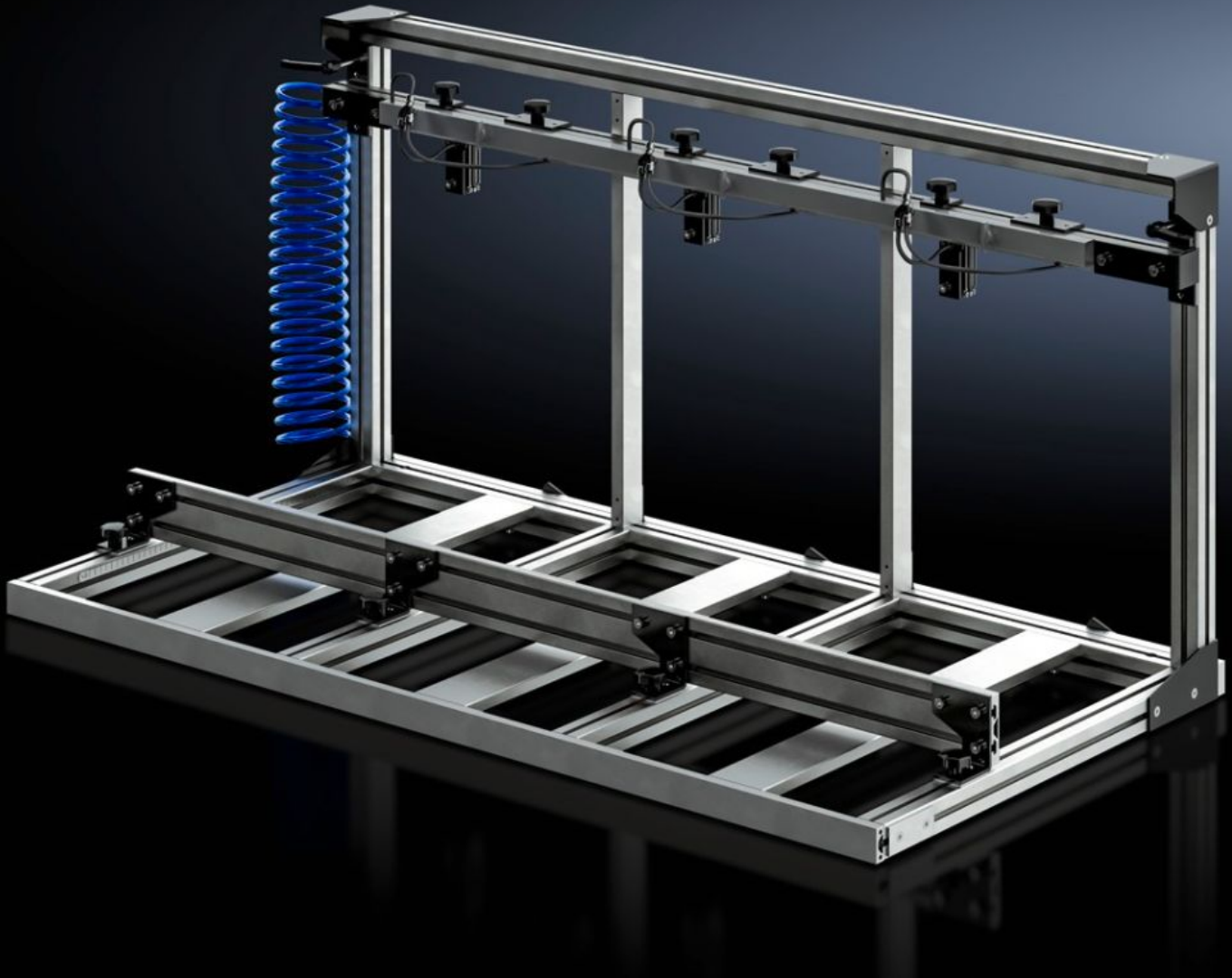


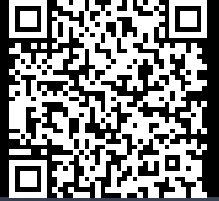

# AS 4050.081

## Clamping frame

State: 03/03/2026 (Source: [rittal.com/uae-en](http://rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.081 - Clamping frame

Parallel machining of enclosures in the cube machining zone of Perforex machining centres BC and Perforex milling terminals MT for shorter setup times and enhanced productivity.

## Features

|                                                           |                                                                                                                                            |
|-----------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|
| Model No.                                                 | AS 4050.081                                                                                                                                |
| Design                                                    | Pneumatic clamping device                                                                                                                  |
| Product description                                       | Enables parallel cube machining of enclosures on Perforex machining centres BC and Perforex milling terminals MT.                          |
| Possible number of terminal Boxes for parallel processing | 4                                                                                                                                          |
| Note                                                      | Use of the clamping frame (Model No. 4050.080) in the machining centre BC (Model No. 4050.230) is only possible with the two-door variant. |
| To fit Model No.                                          | 4050.108<br>4050.230<br>4055.925<br>4055.926<br>4055.921<br>4055.920                                                                       |
| Suitable for                                              | Perforex BC 1008 HS<br>Perforex BC 2014 HS<br>Perforex MT 2201<br>Perforex MT 2201 S<br>Perforex MT 2101<br>Perforex MT 2101 S             |
| Dimensions of clampable enclosures max.                   | Width: 400 mm<br>Height: 400 mm<br>Depth: 400 mm                                                                                           |
| Dimensions of clampable enclosures min.                   | Width: 150 mm<br>Height: 150 mm<br>Depth: 80 mm                                                                                            |
| Packs of                                                  | 1 pc(s).                                                                                                                                   |

# Features

|                       |                                                                                                                                                                                                               |
|-----------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Net weight            | 25 kg                                                                                                                                                                                                         |
| Gross weight          | 25 kg                                                                                                                                                                                                         |
| Customs tariff number | 84669360                                                                                                                                                                                                      |
| ETIM 9                | EC003010                                                                                                                                                                                                      |
| ETIM 8                | EC003010                                                                                                                                                                                                      |
| ECLASS 8.0            | 36609190                                                                                                                                                                                                      |
| Product description   | AS Multiple fastening, BC 1008/2014, Clamping frame for several small enclosures, - 4 clamping positions in the frame, - Pneumatic clamping device, - Min. enclosure dimensions (W x H x D): 150 x 150 x 80mm |