


Rittal – The System.

Faster – better – everywhere.

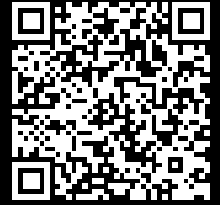

AS 4050.745 Wire end ferrules

State: 17/06/2026 (Source: rittal.com/uae-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.745 - Wire end ferrules loose

With plastic collar.

Features

Model No.	AS 4050.745
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Black
Length	8 mm
AWG	16
Internal diameter	4 mm
For cross-section	1.5 mm ²
DIN colour code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Delivery form	Loose
Packs of	500 pc(s).
Net weight	0.5 kg
Gross weight	0.5 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

Features

Product description	Wire end ferrules for wire processing, 1.5 mm ² , AWG 16, black, loose, 8 mm (wide shaft)
---------------------	------------------------------------------------------------------------------------------------------

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------