


**Rittal – The System.**

Faster – better – everywhere.

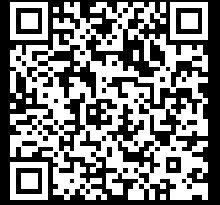

**DK 5302.043**

**Cable tray, depth-variable**

State: 05/04/2026 (Source: [rittal.com/uae-en](http://rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5302.043 - Cable tray, depth-variable for VX IT, TE 8000

For protected cable routing between the front and rear installation area.



## Features

Model No.	DK 5302.043
Product description	For protected cable routing between the front and rear installation area.
Material	Sheet steel
Surface finish	Spray-finished
Colour	RAL 9005
Supply includes	Assembly parts
Installation options	Mounting angle system VX IT standard Mounting angle system TX CableNet TS IT mounting angle system
Mounting position of the 482.6 mm (19") level	VX IT Standard: min. 510 mm - max. 710 mm, with alternative attachment 415 mm - 615 mm TX CableNet: min. 510 mm - max. 710 mm, with alternative attachment 415 mm - 615 mm TS IT: min. 510 mm - max. 710 mm, with alternative attachment 415 mm - 615 mm
Length	350: 550 mm
Packs of	1 pc(s).
Net weight	1.74 kg
Gross weight	1.94 kg

# Features

---

PCF per pack (cradle-to-gate)	7.4 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910
ETIM 9	EC000322
ECLASS 8.0	27400604
Product description	IT cable tray, depth-variable, 350 – 550 mm, sheet steel, zinc-plated, RAL 9005

---