


# Rittal – The System.

Faster – better – everywhere.

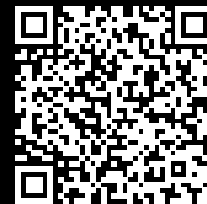

## DK 7109.200

## Light, 1 U

State: 14/05/2024 (Source: [rittal.com/uae-en](https://www.rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7109.200 - Light, 1 U

Ready-to-connect light for installation in the 482.6 mm (19") mounting angles. Fluorescent tube 8 W, 230 V, 50 Hz.

## Features

Model No.	DK 7109.200
Product description	Ready-to-connect light for installation in the 482.6 mm (19") mounting angles. The slot attachment additionally allows it to be fastened to the 25 mm system punchings.
Material	Aluminium, anodised Plastic
Supply includes	Light, 1 U Light Connection cable with earthing-pin plug: Assembly parts
Power consumption	8 W
Length of connection cable	2.5 m
Connection options	Integral connection cable with earthing-pin connector
Light	Fluorescent tubes
Switch (type)	Integral, on/off
Rated impulse withstand voltage, phase to earth	1000 V AC
Rated impulse withstand voltage, phase to phase	500 V AC
Rated insulation voltage	500 V DC/1s
Dimensions	Width: 482.6 mm
Rated operating voltage	230 V, 1~, 50 Hz
Packs of	1 pc(s).
Weight/pack	1.193 kg

# Features

Customs tariff number	94054990
EAN	4028177305557
ETIM 7.0	EC000321
ECLASS 8.0	27189241

# Approvals

Approvals	TÜV
Explanations	Declaration of conformity

# Tender text

Enclosure light for 482.6 mm (19 inch) rack with cable and earthed plug, 8 W

1 light with switch, includes 8 W fluorescent lamp, 2.5 m connection cable with fitted earthing-pin plug.

Material: Aluminium, anodised plastic