


Rittal – The System.

Faster – better – everywhere.

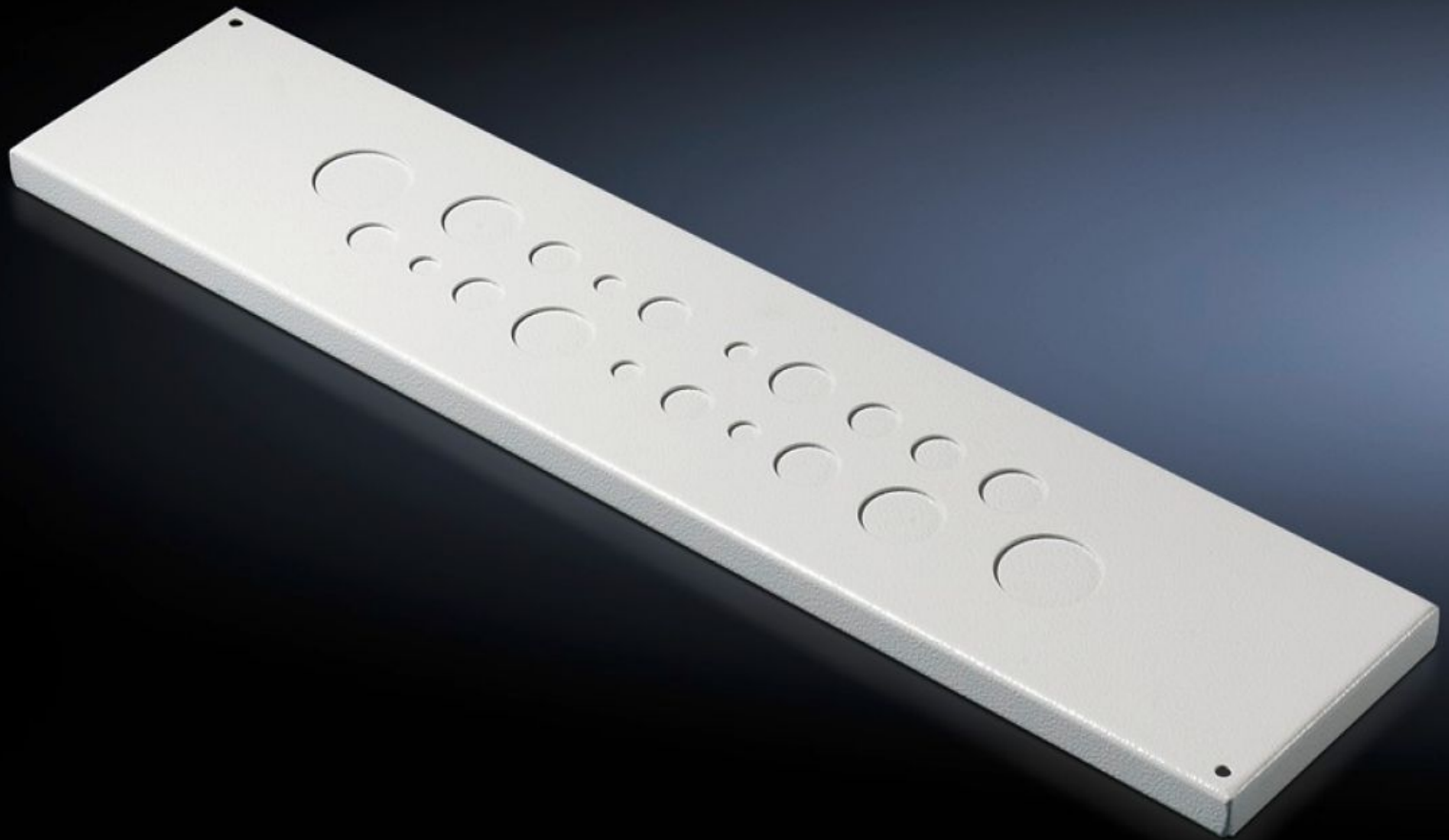

EL 7705.235

Gland plate for metric cable glands

State: 17/04/2026 (Source: rittal.com/uae-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



EL 7705.235 - Gland plate for metric cable glands for EL

Folded gland plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands.

Features

| | |
|-----------------------------------|--|
| Model No. | EL 7705.235 |
| Product description | Folded gland plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands M12, M20, M25, M32, M40. |
| Material | Sheet steel, 1.5 mm |
| Colour | RAL 7035 |
| No. of metric knockouts | 4 x M12 8 x M20 6 x M25 1 x M32 1 x M40 |
| Dimensions | Width: 599 mm Depth: 133.5 mm |
| Protection category to IEC 60 529 | IP 55 |
| Packs of | 1 pc(s). |
| Net weight | 1.55 kg |
| Gross weight | 1.64 kg |
| PCF per pack (cradle-to-gate) | 6.2 kg CO2 eq (Cat B) |
| Note on PCF category | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number | 73079100 |
| ETIM 9 | EC000211 |
| ECLASS 8.0 | 27142421 |
| Product description | EL Gland plate for metric cable glands, WxD: 599x133,5 mm, For EL |