


Rittal – The System.

Faster – better – everywhere.

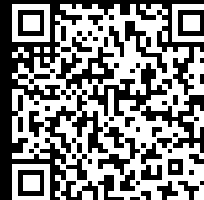

DK 7856.191 PSM socket modules

State: 16/07/2025 (Source: rittal.com/uae-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7856.191 - PSM socket modules

The various modules may be inserted into the support rail in any combination.

Features

| | |
|-----------------------------------|--|
| Model No. | DK 7856.191 |
| Design | non-switchable |
| Product description | The modular system facilitates basic configuration of the racks, thanks to a vertical support rail with single-/3-phase infeed. The various socket modules to supply the active components may be snap-fitted into the support rail. The various modules, earthing pins, IEC320 etc. may be inserted into the support rail in any combination. This is easily achieved, even by non-electricians, thanks to the shock hazard protected plug & play system. |
| Material | Section: Aluminium, anodised Socket inserts: Plastic (PA6 GF 30 V1) |
| Rated operating voltage | 110 V – 230 V AC, 50/60 Hz |
| Rated current | 16 A |
| Rated current (max.) | 16 A |
| Required number of module slots | 1 |
| Dimensions | Width: 52 mm Height: 250 mm Depth: 45 mm |
| Operating temperature range | 5 °C...45 °C |
| Ambient humidity (non-condensing) | 5...95 % |
| Sockets | 4 x CH (type J, SEV 1011) |
| Packs of | 1 pc(s). |
| Net weight | 0.29 |
| Gross weight | 0.34 |
| Customs tariff number | 85369001 |

Features

| | |
|------------|---------------|
| EAN | 4028177692381 |
| ETIM 9 | EC000330 |
| ECLASS 8.0 | 27142604 |