

Rittal – The System.



Faster – better – everywhere.



KL 1581.000

Plastic cable gland plates

State: 19/02/2026 (Source: rittal.com/uk-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

KL 1581.000 - Plastic cable gland plates with PG knockouts

With pre-punched PG holes for cable glands.

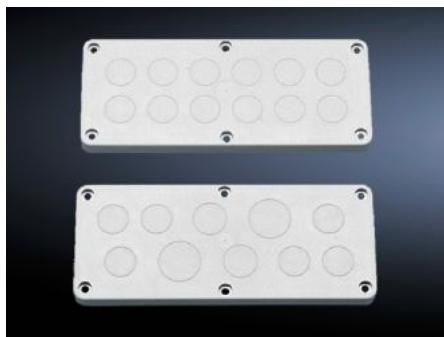

Features

Model No.	KL 1581.000
Product description	With pre-punched PG holes for cable glands. Use seal for standard gland plates.
Material	ABS
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	12
Number x PG diameter	12 x 13.5
Dimensions	Width: 220 mm Depth: 90 mm
To fit	Enclosure type: KL
Gland plate	Size: 2
Operating temperature range	-40 °C...70 °C
Protection category to IEC 60 529	IP 55 if installed correctly
Number knockouts	12
Packs of	5 pc(s).

Features

Net weight	0.505 kg
Gross weight	0.604 kg
Customs tariff number	73079100
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	KL Plastic cable gland plate, with PG knock-outs, WD: 220x90 mm, size: 2, PG knockouts: 13.5