


# Rittal – The System.

Faster – better – everywhere.

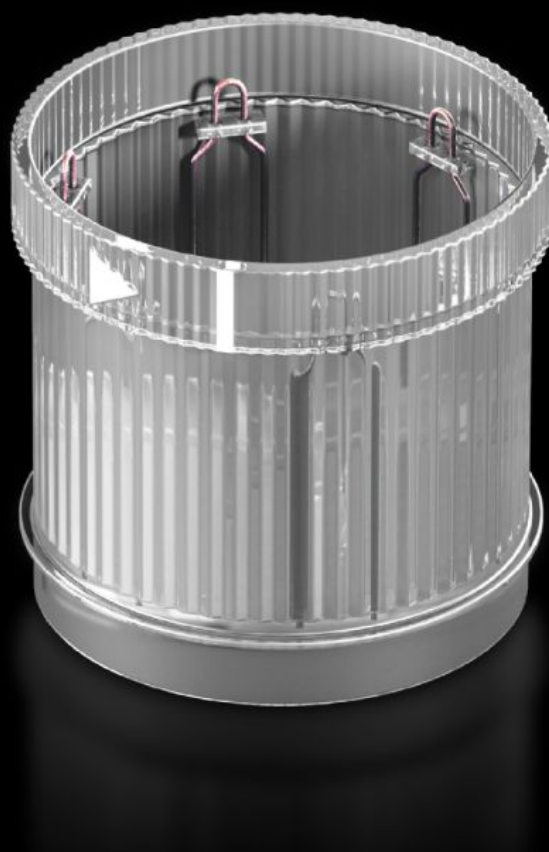

## SG 2372.031

### LED steady light component

State: 13/07/2025 (Source: [rittal.com/uk-en](https://www.rittal.com/uk-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SG 2372.031 - LED steady light component for signal pillar, modular

With 360° signal transmission thanks to optimised prism system.

## Features

Model No.	SG 2372.031
Design	LED steady light component
Benefits	With 360° signal transmission thanks to optimised prism system Configuration of up to five components with the same voltage.
Function principle	A modular layout is possible with connection, optical and acoustic components and a label panel
Material	Enclosure of polyamide Cap: Transparent polycarbonate
Colour	Clear
Protection category to IEC 60 529	IP 65 if a cover or acoustic component is fitted at the top
Rated operating voltage	24 V (AC/DC)
Packs of	1 pc(s).
Net weight	0.07
Gross weight	0.073
Customs tariff number	85311095
EAN	4028177953741
ETIM 9	EC000232
ETIM 8	EC000232
ECLASS 8.0	27371220

## Approvals

# Approvals

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity