


Rittal – The System.

Faster – better – everywhere.

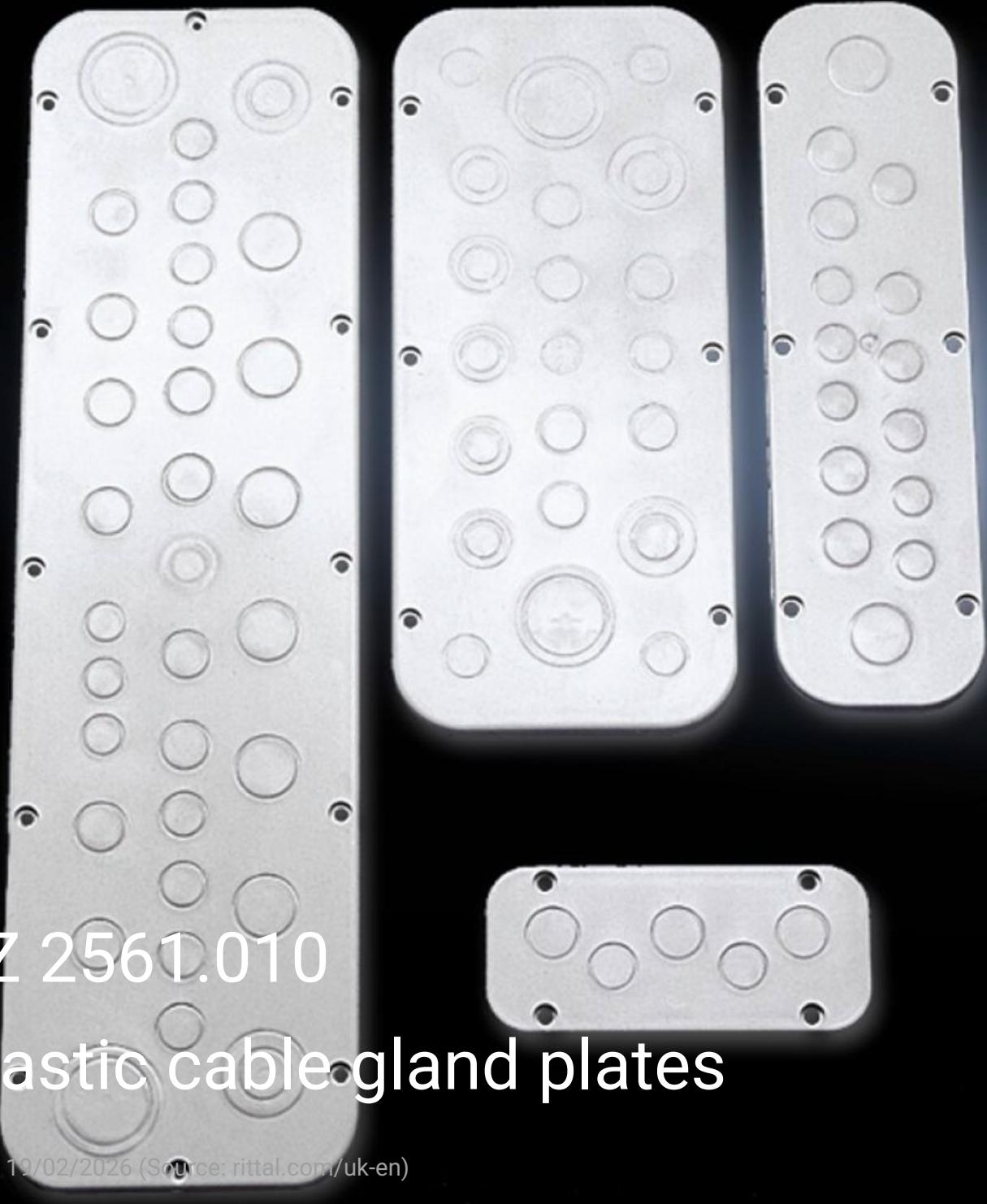

SZ 2561.010

Plastic cable gland plates

State: 10/02/2026 (Source: rittal.com/uk-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2561.010 - Plastic cable gland plates with metric knockouts

With pre-punched holes for cable glands.

Features

Model No.	SZ 2561.010
Product description	With pre-punched holes for cable glands. Use seal for standard gland plates.
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	3 x M16 5 x M20 4 x M25 2 x M32 2 x M40
Dimensions	Width: 330 mm Depth: 90 mm
To fit	Enclosure type: AE
Gland plate	Size: 3
Operating temperature range	-40 °C...70 °C
Protection category to IEC 60 529	IP 55 if installed correctly
Number knockouts	3 5 4 2 2

Features

Metric diameter	M16 M20 M25 M32 M40
Packs of	10 pc(s).
Net weight	1.13 kg
Gross weight	1.396 kg
Customs tariff number	39269097
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Plastic cable gland plate, with metric knock-outs, WD: 330x90 mm, size: 3