


# Rittal – The System.

Faster – better – everywhere.

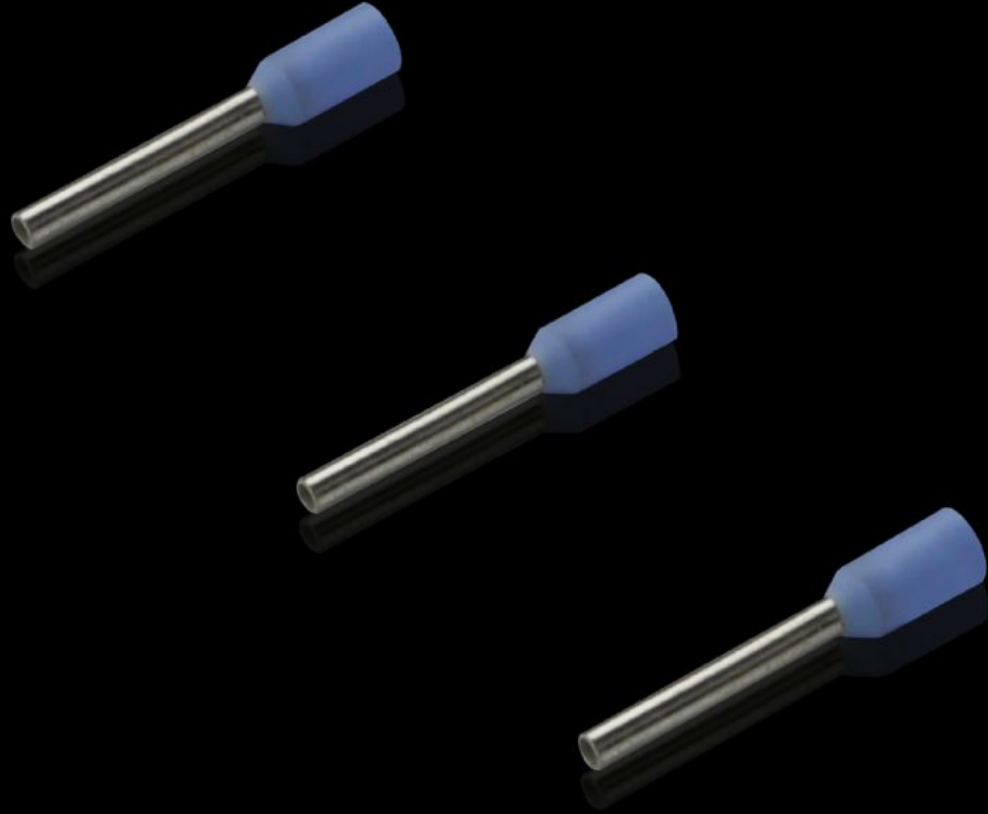

## AS 4050.754 Wire end ferrules

State: 13/05/2026 (Source: [rittal.com/uk-en](http://rittal.com/uk-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.754 - Wire end ferrules loose

With plastic collar.

## Features

|                          |   |
|--------------------------|---|
| Model No.                | AS 4050.754   |
| Product description      | With plastic collar.  |
| Technical specifications | Heat-resistant to 105 °C  |
| Material                 | E-Cu, galvanic tin-plated<br>Plastic collar: Polypropylene  |
| Colour                   | Light blue  |
| Length                   | 8 mm  |
| AWG                      | 24  |
| Internal diameter        | 1.8 mm  |
| Rittal colour code       | Yes   |
| For cross-section        | 0.25 mm <sup>2</sup>  |
| Note                     | UL-certified in conjunction with the relevant tools, such as crimping machines.<br>For bespoke advice, please contact your Rittal sales consultant. |
| Standards                | AEH DIN 46228   |
| Delivery form            | Loose   |
| Packs of                 | 500 pc(s).  |
| Net weight               | 0.5 kg  |
| Gross weight             | 0.026 kg  |
| Customs tariff number    | 85369010  |
| ETIM 9                   | EC000005  |
| ETIM 8                   | EC000005  |
| ECLASS 8.0               | 36659290  |

# Features

---

Product description

Wire end ferrules for manual preassembly, 0.25 mm<sup>2</sup>, AWG 24, 8 mm, light blue, loosely packed, 500 pc(s).

# Approvals

---

Approvals

UL + C-UL (listed)  
UR