


Rittal – The System.

Faster – better – everywhere.

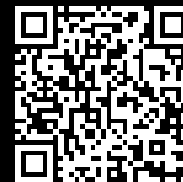

AS 4054.008

Crimping pliers

State: 24/08/2025 (Source: [rittal.com/uk-en](https://www.rittal.com/uk-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4054.008 - Crimping pliers for wire end ferrules

For use with wire end ferrules with no insulating collar to DIN 46228 Part 1 and wire end ferrules with insulating collar to DIN 46228 Part 4.



Features

| | |
|--------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No. | AS 4054.008 |
| Design | Straight |
| Product description | For use with wire end ferrules with no insulating collar to DIN 46228 Part 1 and wire end ferrules with insulating collar to DIN 46228 Part 4. |
| Benefits | Minimal effort required with large wire cross-sections Uniformly high quality compression Marked die stations for precise machining of the relevant cross-sections Releasable ratchet |
| Material | High-quality special tool steel |
| Surface finish | Matt, plated |
| Colour | Handle: Anthracite and Rittal Power Pink |
| Compression | WM crimp |
| Direction of cable entry | Side |
| Dimensions | Height: 68 mm Length: 256 mm |
| AWG | 2 - 1 |
| For cross-section | 35 - 50 mm ² |
| Packs of | 1 pc(s). |

Features

| | |
|-----------------------|---------------|
| Net weight | 0.64 |
| Gross weight | 0.69 |
| Customs tariff number | 82032000 |
| EAN | 4028177807617 |
| ETIM 9 | EC000168 |
| ETIM 8 | EC000168 |
| ECLASS 8.0 | 21043811 |