


**Rittal – The System.**

Faster – better – everywhere.

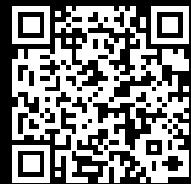

# AS 4054.024

## Crimping pliers

State: 14/02/2026 (Source: [rittal.com/uk-en](http://rittal.com/uk-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4054.024 - Crimping pliers for ring terminals

For use with non-insulated ring terminals



## Features

|                       |   |
|-----------------------|---|
| Model No.             | AS 4054.024   |
| Design                | Straight  |
| Product description   | For use with non-insulated ring terminals.  |
| Benefits              | Releasable ratchet<br>Optimised lever transmission means that only minimal actuator forces are required, even with large cross-sections |
| Material              | High-quality special tool steel   |
| Surface finish        | Matt, plated  |
| Colour                | Handle: Anthracite and Rittal Power Pink  |
| Compression           | Indent crimp  |
| Dimensions            | Height: 68 mm<br>Length: 256 mm   |
| AWG                   | 8 - 4   |
| For cross-section     | 10 - 25 mm <sup>2</sup>   |
| Packs of              | 1 pc(s).  |
| Net weight            | 0.52  |
| Gross weight          | 0.67  |
| Customs tariff number | 82032000  |

# Features

---

|            |               |
|------------|---------------|
| EAN        | 4028177807655 |
| ETIM 9     | EC000168      |
| ETIM 8     | EC000168      |
| ECLASS 8.0 | 21043811      |

---