


Rittal – The System.

Faster – better – everywhere.

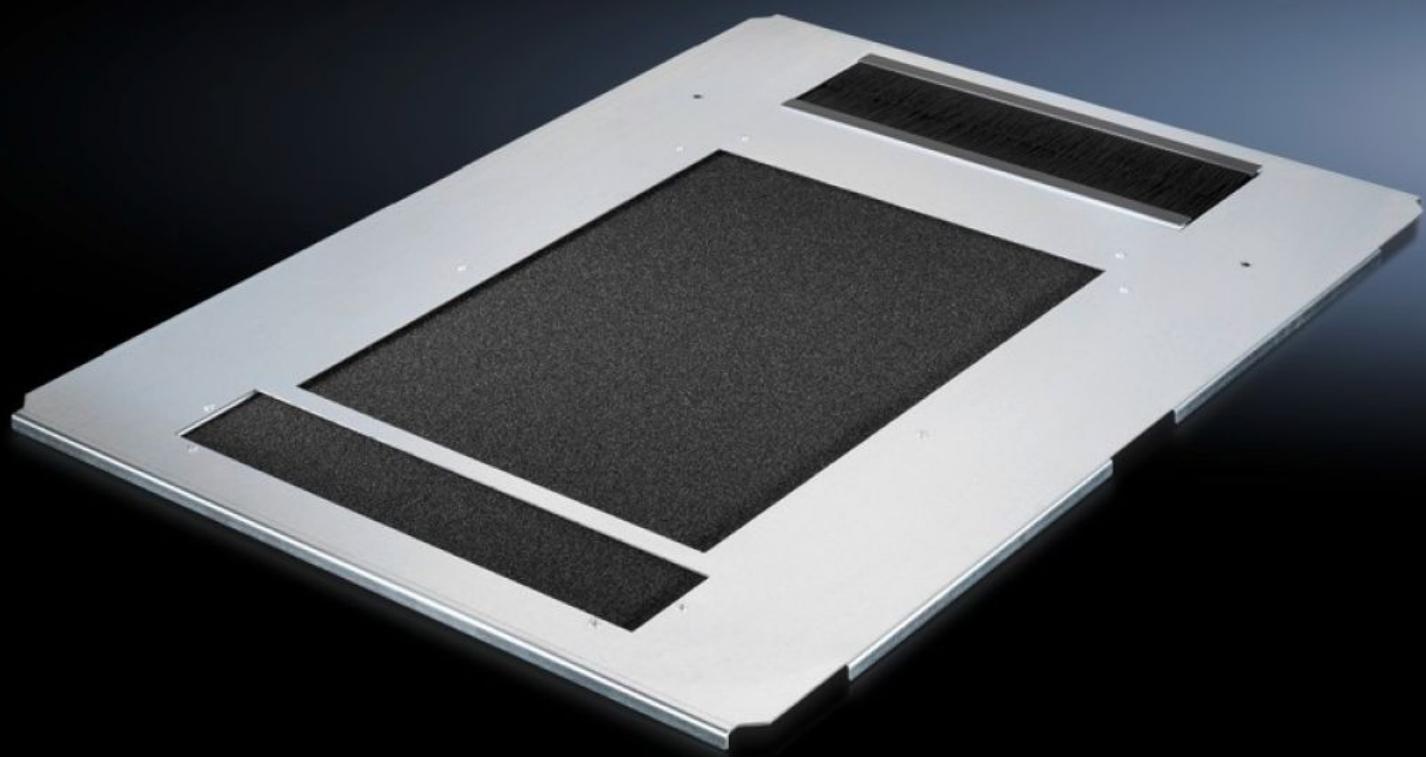

DK 5502.330

Gland plate, one-piece, vented

State: 15/02/2026 (Source: rittal.com/uk-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

DK 5502.330 - Gland plate, one-piece, vented for TS IT, TX CableNet

Potential equalisation is provided via assembly components and earthing points. The gland plate set is used to conceal the entire base opening.

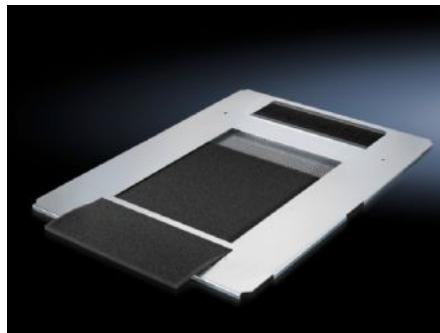

Features

Model No.	DK 5502.330
Product description	To completely cover the open base assembly in one piece. Perforated over the entire surface. This allows cold air to flow in from the base or base/plinth area. This ensures the inflow of cold air, particularly in enclosures with rack climate control. With a brush strip at the rear for user-friendly cable entry from below across the entire enclosure width. Integral guides permit simple accommodation of a filter mat, which is also readily replaced.
Material	Sheet steel Brush strip: Plastic, UL 94-HB Filter mat: Foamed plastic
Surface finish	Zinc-plated
Supply includes	Gland plate, one-piece, vented, with cable entry at the rear Filter mat Assembly parts
To fit	Enclosure type: TS IT TX CableNet Width: 800 mm Depth: 800 mm
Packs of	1 pc(s).

Features

Net weight	6.08
Gross weight	6.18
Customs tariff number	94039910
EAN	4028177707818
ETIM 9	EC002620
ECLASS 8.0	27189261

Tender text

Grand plate, one-piece, vented,
With cable entry at the rear
For TS, TS IT, TX CableNet
WxD: 800 x 800 mm
Sheet steel
Brush strip: Plastic, UL 94-HB
Filter mat: Foamed plastic