


Rittal – The System.

Faster – better – everywhere.

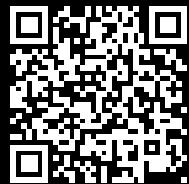

WM 1060.250

WM wall-mounted enclosure

State: 1/26/2026 (Source: ittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



WM 1060.250 - WM wall-mounted enclosure single-door

These single door wallmount enclosures can be used for virtually any application. The WM series ensures NEMA protection through a secure locking system, foamed-in-place gasket, and knife-edge sealing surface. Features include a cold rolled steel body and door, and a zinc plated mounting panel.



Features

| | |
|--------------------------------------|--|
| Model No. | WM 1060.250 |
| Material | Door: Carbon steel, all-round foamed-in PU seal Housing: Carbon steel |
| Surface finish | Housing and door: Dipcoat primed, powder-coated on the outside, textured paint Mounting panel: Zinc-plated |
| Color | RAL 7035 |
| Supply includes | Housing with door(s) Door hinged on left Mounting plate Rear wall mounting holes Quarter turn latch with slotted head insert |
| Dimensions | Width: 600 mm Height: 600 mm Depth: 210 mm Width: 23.6 " Height: 23.6 " Depth: 8.27 " |
| Dimensions of mounting plate (W x H) | 549 mm x 570 mm 21.6 " x 22.4 " |

Features

| | |
|-------------------------------------|--|
| Protection category NEMA | NEMA 1 NEMA 3R NEMA 4 NEMA 12 |
| Material thickness - door | 2 mm 0.08 " |
| Material thickness - enclosure | 1.5 mm 0.06 " |
| Material thickness – mounting plate | 2.5 mm 0.1 " |
| Packaging unit | 1 pc(s). |
| Net weight | 47.399 |
| Gross weight | 50.265 |
| Customs tariff number | 8538100000 |
| EAN | 4028177532700 |
| UPC-Code | 83109 |

Approvals

| | |
|--------------|---------------------------|
| Approvals | UL + C-UL (listed) |
| Explanations | Declaration of conformity |
