
 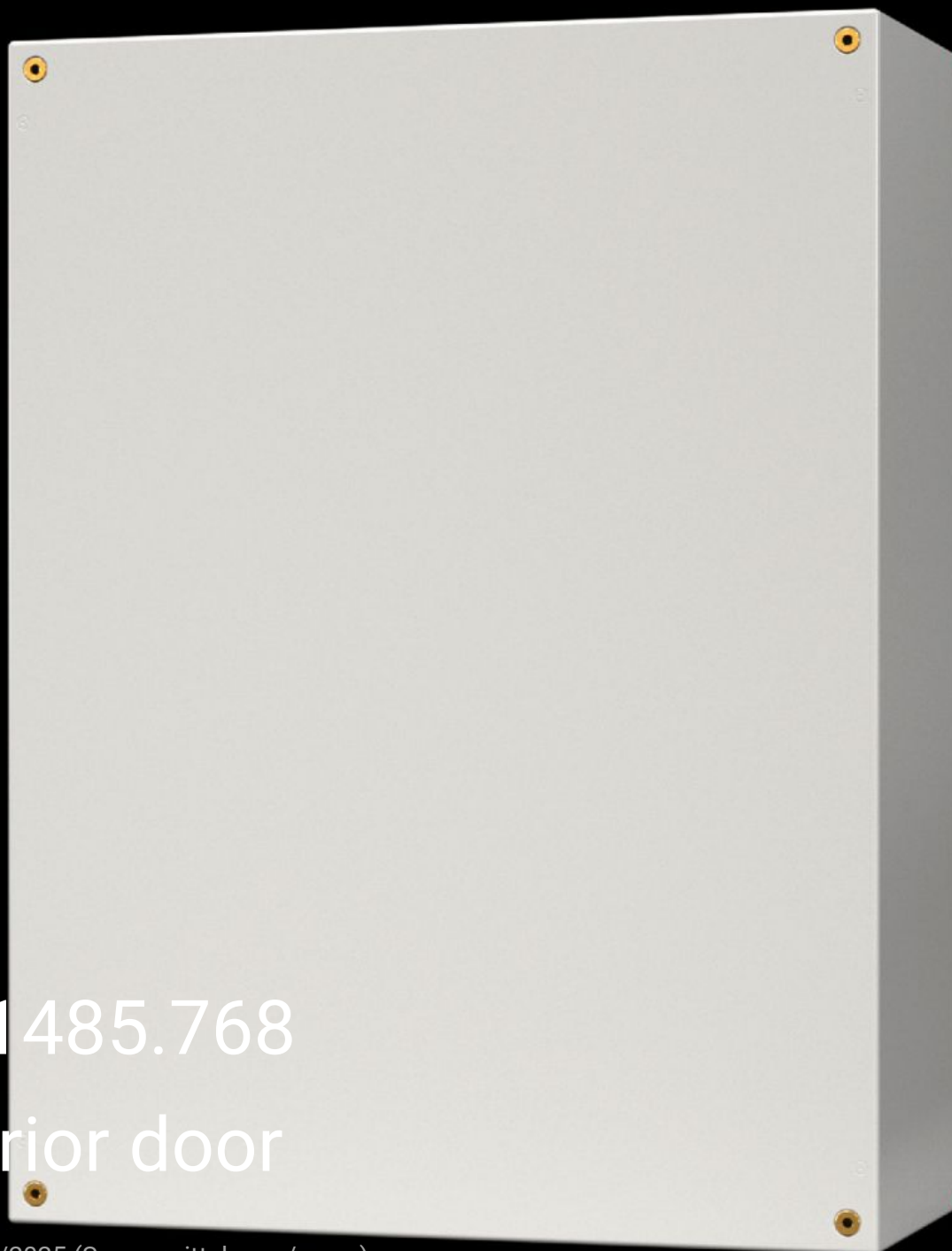


Rittal – The System.

Faster – better – everywhere.



SZ 1485.768
Interior door

State: 7/25/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 1485.768 - Interior door for AX Fiberglass-Reinforced Polyester Enclosures

For reliable access protection. Separation of the operating and equipment levels.

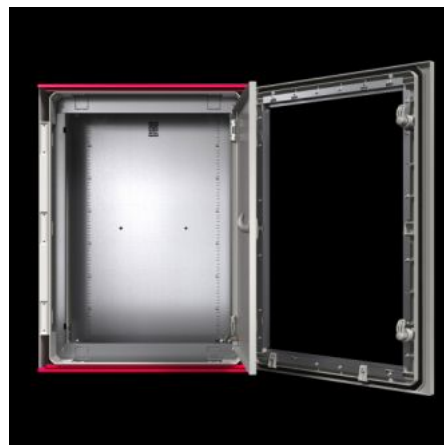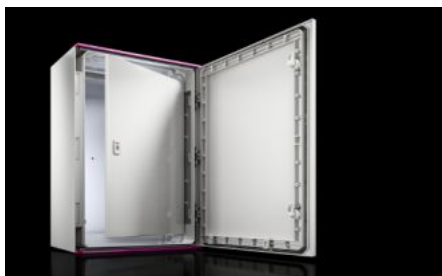

Features

Model No.	SZ 1485.768
Material	Door and door frame: Carbon steel
Surface finish	Door: Powder-coated, textured paint Door frame: Zinc-plated
Color	Door: RAL 7035
Supply includes	Door Cam lock with 3 mm double-bit insert Assembly screws
Installation options	In AX fiberglass-reinforced polyester on fixing domes in the side walls
Note	Standard double-bit lock insert may be exchanged for 27 mm lock inserts, type A
Suitable for enclosure type	AX plastic
Suitable for width	600 mm 23.6 "
Suitable for height	800 mm 31.5 "

Features

Material thickness - door	1 mm 0.04 "
Door opening angle	105°
Packaging unit	1 pc(s).
Net weight	5.32
Gross weight	5.62
Customs tariff number	94039910
EAN	4028177965850
ETIM 9	EC000747
ETIM 8	EC000747
ECLASS 8.0	27182204