


**Rittal – The System.**

Faster – better – everywhere.

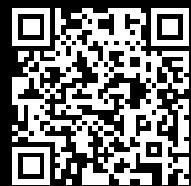

# KL 1514.510

## KL Terminal Boxes

State: 1/25/2026 (Source: [ittal.com/us-en](https://ittal.com/us-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# KL 1514.510 - KL Terminal Boxes without gland plate

Spray-finished housing with sheet steel cover, without gland panel. Protection category IP 66.

## Features

Model No.	KL 1514.510
Material	Housing: Carbon steel Cover: Carbon steel, all-round foamed-in PU seal
Surface finish	Housing and cover: Dipcoat primed, powder-coated on the outside, textured paint
Color	RAL 7035
Supply includes	Housing with cover Quick-release fasteners including plastic bushings
Protection category NEMA	NEMA 4
Protection category IP to EN 60 529	IP 66
IK code	IK08
Dimensions	Width: 150 mm Height: 150 mm Depth: 80 mm Width: 5.91 " Height: 5.91 " Depth: 3.15 "
Material thickness - cover	1.25 mm 0.05 "
Material thickness - enclosure	1.25 mm 0.05 "
Base material	Carbon steel
Packaging unit	1 pc(s).
Net weight	1.012
Gross weight	1.212

# Features

---

Customs tariff number 73269098

---

EAN 4028177251267

---

E-Number Sweden E3404676

---

ECLASS 8.0 27180101

# Approvals

---

Approvals Bureau Veritas  
DNV-GL  
Lloyds Register of Shipping  
UL + C-UL (listed)

---

Explanations Manufacturer's declaration  
Declaration of conformity UK