

Rittal – The System.

Faster – better – everywhere.



KL 1527.510

KL Terminal Boxes

State: 1/24/2026 (Source: rittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

KL 1527.510 - KL Terminal Boxes without gland plate

Spray-finished housing with sheet steel cover, without gland panel. Protection category IP 66.

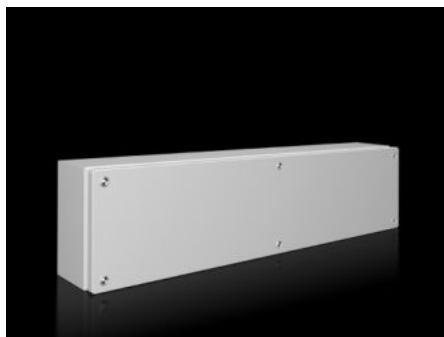

Features

Model No.	KL 1527.510
Material	Housing: Carbon steel Cover: Carbon steel, all-round foamed-in PU seal
Surface finish	Housing and cover: Dipcoat primed, powder-coated on the outside, textured paint
Color	RAL 7035
Supply includes	Housing with cover Quick-release fasteners including plastic bushings
Protection category NEMA	NEMA 4
Protection category IP to EN 60 529	IP 66
IK code	IK08
Dimensions	Width: 800 mm Height: 200 mm Depth: 120 mm Width: 31.5 " Height: 7.87 " Depth: 4.72 "
Material thickness - cover	1.25 mm 0.05 "

Features

Material thickness - enclosure	1.25 mm 0.05 "
Base material	Carbon steel
Packaging unit	1 pc(s).
Net weight	6.131
Gross weight	6.454
Customs tariff number	73269098
EAN	4028177251328
E-Number Sweden	E3404683
ETIM 9	EC000261
ETIM 8	EC000261
ECCLASS 8.0	27180101

Approvals

Approvals	Bureau Veritas DNV-GL Lloyds Register of Shipping UL + C-UL (listed)
Explanations	Manufacturer's declaration Declaration of conformity UK
