


Rittal – The System.

Faster – better – everywhere.

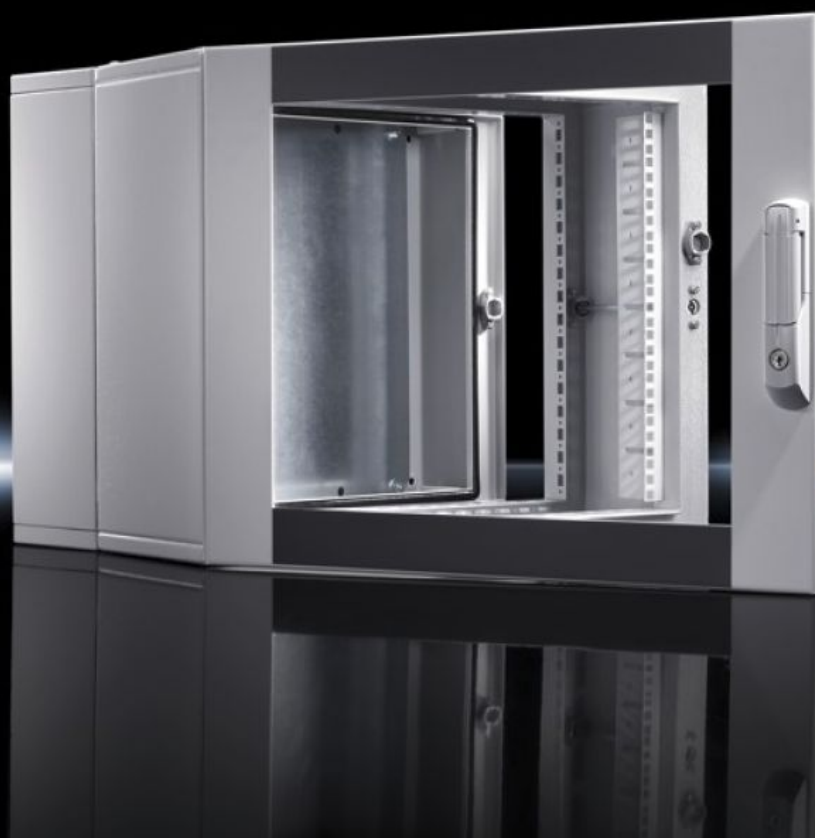

EL 2271.605

Wall-mounted enclosures EL, 3-part

State: 7/13/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



EL 2271.605 - Wall-mounted enclosures EL, 3-part with mounting plate and profile rails, static installation

Wall-mounted housing 3-part, pre-configured with: Solid flange plate, top and bottom, mounting plate is supplied loose. Protection category IP 55.

Features

| | |
|---------------------|---|
| Model No. | EL 2271.605 |
| Version | Wall-mounted housing IT with mounting plate and profile rails, static installation |
| Product description | Wall-mounted enclosure with hinged door provides optimum accessibility. |
| Material | Wall and hinged part: Carbon steel, 1.5 mm Viewing window: Single-pane safety glass, 3 mm |
| Surface finish | Powder-coated |
| General color | RAL 7035 |
| Color | Wall and hinged part: RAL 7035 Viewing door: RAL 7035/7015 (slate gray) |
| Supply includes | Wall section with flange (gland) plate, top and bottom, and mounting plate (supplied loose). Hinged part with 25 mm pitch pattern in the front and rear frame, two 19" profile angles at the front, fixed in place Designer viewing door 1 enclosure key double bit no. 5 Comfort handle for lock inserts and 2-point locking Security lock 3524 E |
| Height units | 21 U |
| Dimensions | Width: 600 mm Height: 1,012 mm Depth: 473 mm Width: 23.6 " Height: 39.8 " Depth: 18.6 " |

Features

| | |
|---------------------------------------|--|
| Installation depth | 420 mm 16.5 " |
| Clearances | Clearance width: 502 mm Clearance height: 949 mm Clearance width: 19.8 " Clearance height: 37.4 " |
| Depth hinged part | 316 mm 12.4 " |
| Dimensions of mounting plate (W x H) | 485 mm x 965 mm 19.1 " x 38 " |
| Depth of wall section | 135 mm 5.31 " |
| IK code | IK08 |
| Load capacity of hinged part (static) | 750 N 168.607 lbf. |
| Base material | Carbon steel |
| Protection category IP to EN 60 529 | IP 55 |
| Packaging unit | 1 pc(s). |
| Net weight | 53.2 |
| Gross weight | 56 |
| Customs tariff number | 94032080 |
| EAN | 4028177324435 |
| ETIM 9 | EC002500 |
| ETIM 8 | EC002500 |
| ECLASS 8.0 | 27180208 |

Approvals

Approvals

Approvals

Lloyds Register of Shipping
UL + C-UL (listed)