

Rittal – The System.

Faster – better – everywhere.



SR 2331.700

Pivoting Frame, large, without trim panel

State: 5/16/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SR 2331.700 - Pivoting Frame, large, without trim panel for TS, VX SE, 600 mm and 1200 mm wide enclosures

For 600 mm and 1200 mm wide enclosures, 22 - 45 U, without trim panel, to mount 482.6 mm (19") equipment.

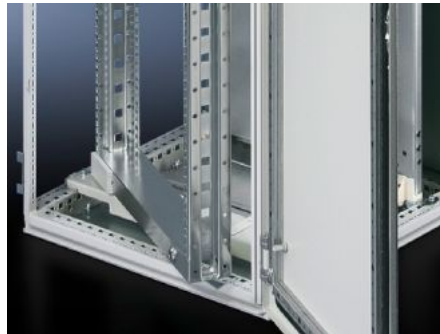

Features

Model No.	SR 2331.700
Product description	To mount 482.6 mm (19") equipment.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Cam with double-bit lock insert Parts for attaching to the installation kit
Mounting tip	Depending on the installation situation TS punched sections with mounting flange, 23 x 73 mm, or TS punched sections with mounting flange, 17 x 73 mm are required
Note	see "Technical Details" for other expansion options
Suitable for	Enclosure type: TS Width: = 600 mm = 1,200 mm Height: ≥ 1,600 mm Enclosure type: TS Width: = 23.6 " = 47.2 " Height: ≥ 63 "
Height units	31 U

Features

Suitable for enclosure type	TS
Packaging unit	1 pc(s).
Weight/packaging unit	11.82 kg 26.1 lb.
Customs tariff number	94039910
EAN	4028177021426
ETIM 7.0	EC002620
ECLASS 8.0	27189261