
 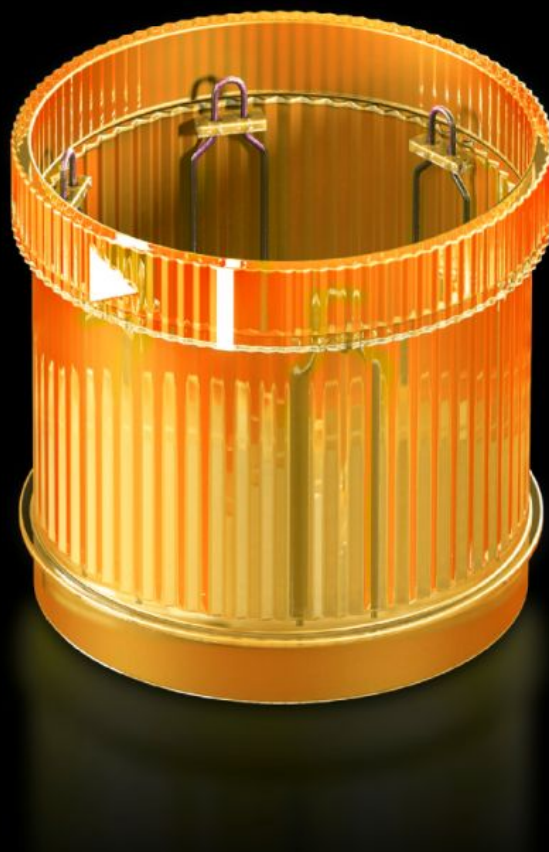


Rittal – The System.

Faster – better – everywhere.



SG 2370.171

LED steady light component

State: 12/16/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SG 2370.171 - LED steady light component for signal pillar, modular

With 360° signal transmission due to optimized prism system.

Features

| | |
|-------------------------------------|---|
| Model No. | SG 2370.171 |
| Version | LED steady light component |
| Benefits | With 360° signal transmission thanks to optimized prism system Configuration of up to five components with the same voltage. |
| Function principle | A modular layout is possible with connection, optical and acoustic components and a label panel |
| Material | Housing of polyamide Cap: Transparent polycarbonate |
| Color | Yellow |
| Protection category IP to EN 60 529 | IP 65, when cover or acoustic component is mounted on top |
| Rated operating voltage | 230 V |
| Packaging unit | 1 pc(s). |
| Net weight | 0.072 |
| Gross weight | 0.073 |
| Customs tariff number | 85311095 |
| EAN | 4028177953611 |
| ETIM 9 | EC000232 |
| ETIM 8 | EC000232 |
| ECLASS 8.0 | 27371220 |

Approvals

| | |
|--------------|---------------------------|
| Approvals | UL + C-UL (listed) |
| Explanations | Declaration of conformity |