


Rittal – The System.

Faster – better – everywhere.

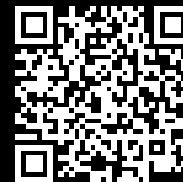

SZ 2422.000

Spacer

State: 7/27/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2422.000 - Spacer for roof plate

For raising the roof for ventilation purposes, available in three different heights. Not suitable for crane transport.

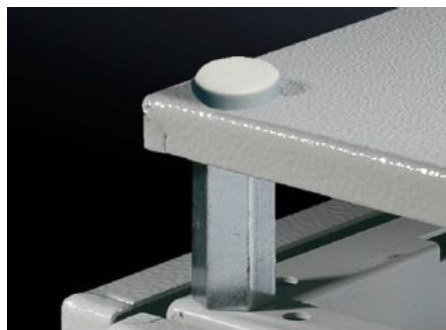

Features

Model No.	SZ 2422.000
Product description	For raising the roof for ventilation purposes, available in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly components
Mounting tip	Not suitable for crane transportation
Dimensions	Height: 10 mm Height: 0.39 "
Dimensions	Thread: M12
Suitable for	Enclosure type: VX TS
Packaging unit	4 pc(s).
Net weight	0.12
Gross weight	0.161
PCF/VE (cradle-to-gate)	0.6 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

Features

Customs tariff number	83024900
EAN	4028177022775
E-Number Sweden	E7239751
ETIM 9	EC002625
ETIM 8	EC002625
ECLASS 8.0	27189234