

Rittal – The System.

Faster – better – everywhere.



SZ 2423.000

Spacer

State: 2/1/2026 (Source: ittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2423.000 - Spacer for roof plate

For raising the roof for ventilation purposes, available in three different heights. Not suitable for crane transport.

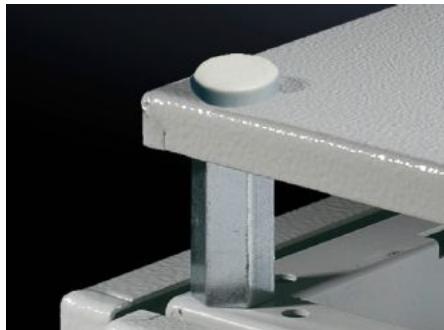

Features

Model No.	SZ 2423.000
Product description	For raising the roof for ventilation purposes, available in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly components
Mounting tip	Not suitable for crane transportation
Dimensions	Height: 20 mm Height: 0.79 "
Dimensions	Thread: M12
Suitable for	Enclosure type: VX TS
Packaging unit	4 pc(s).
Net weight	0.216
Gross weight	0.255
PCF/VE (cradle-to-gate)	1 kg CO ₂ eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

Features

Customs tariff number 73269098

EAN 4028177022799

E-Number Sweden E7239675

ETIM 9 EC002625

ETIM 8 EC002625

ECLASS 8.0 27189234